

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® MS-XL	52115730 14.11.2013

 
Especially for thick walls
Maximum reliability
Wide, variable clamping ranges
Optimum strain relief



Good chemical resistance



Mechanical resistance



Optimum strain relief



Robust



Temperature-resistant



Variety of approval certifications



Application range

With long connection thread for applications involving a thicker wall.

Design

PG connection thread

Note

Counter nut to be used: SKINDICHT® SM

Refer to SKINTOP® PG accessories for suitable accessories

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Product Management	Document: SKINTOP® MS-XL	1 / 3
--------------------	--------------------------	-------


U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® MS-XL	52115730 14.11.2013

Technical Data

Article designation / size:	MS 13,5 XL
Clamping range ØF (mm):	5 - 12
SW (mm):	22
Overall length, C (mm):	39,5
Thread length, D (mm):	12
Pieces / PU:	50
Caution:	Refer to Appendix T21 for the installation dimensions and torques
Material:	Body: nickel-plated brass Insert: polyamide Sealing ring: CR O-ring: NBR
Protection rating:	IP 68 - 5 bar
Temperature range:	-30°C to +100°C

Product Management	Document: SKINTOP® MS-XL	2 / 3
--------------------	--------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® MS-XL	52115730 14.11.2013

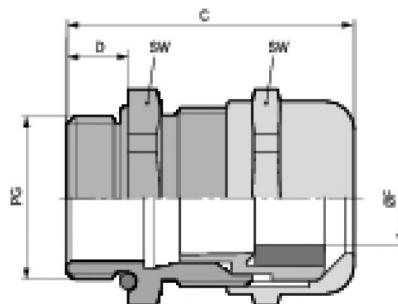

Product Management	Document: SKINTOP® MS-XL	3 / 3
--------------------	--------------------------	-------