

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® ST	53015290 14.11.2013

Various accessories (e.g. multiple sealing inserts)
 High oil-resistance for maximum reliability
 Permanent vibration protection
 Optimum strain relief
 Wide, variable clamping ranges



Good chemical resistance



Wide clamping range



Mechanical resistance



Optimum strain relief



Temperature-resistant



Variety of approval certifications



Application range

Used in areas where cables and wires need to be safely inserted into housings
 Machine and equipment manufacturing
 Photovoltaic
 Automation technology

Design

PG connection thread

Norm references / Approvals

UL File Nr. E79903

Note

Refer to SKINTOP® PG accessories for suitable accessories
 Counter nut to be used: SKINTOP® GMP-GL

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Product Management	Document: SKINTOP® ST	1 / 3
--------------------	-----------------------	-------


U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® ST	53015290 14.11.2013

Technical Data

Article designation / size:	ST 48
Clamping range ØF (mm):	39 - 44
SW (mm):	65
Overall length, C (mm):	69
Thread length, D (mm):	14
Pieces / PU:	5
Caution:	Refer to Appendix T21 for the installation dimensions and torques
Colour delivered:	Silver grey (RAL 7001) Light grey (RAL 7035) Black (RAL 9005), UV-resistant
Material:	Body: Polyamide Seal: CR
Tests:	GGVS: TÜ.EGG.020-95
Protection rating:	IP 68 - 5 bar
Temperature range:	-20°C to +80°C

Product Management	Document: SKINTOP® ST	2 / 3
--------------------	-----------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® ST	53015290 14.11.2013

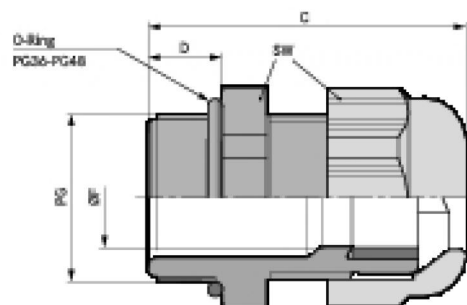

Product Management	Document: SKINTOP® ST	3 / 3
--------------------	-----------------------	-------