

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® STR	53015330 14.11.2013

 
High oil-resistance for maximum reliability
 Permanent vibration protection
 Optimum strain relief
 Wide, variable clamping ranges
 Various accessories (e.g. multiple sealing inserts)



Good chemical resistance



Mechanical resistance



Optimum strain relief



Temperature-resistant



Variety of approval certifications



Application range

With reducing seal insert, to seal cables with smaller outer diameters.

Design

PG connection thread

Norm references / Approvals

UL File Nr. E79903

Note

Refer to SKINTOP® PG accessories for suitable accessories
 Counter nut to be used: SKINTOP® GMP-GL

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Product Management	Document: SKINTOP® STR	1 / 3
--------------------	------------------------	-------


U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® STR	53015330 14.11.2013

Technical Data

Article designation / size:	STR 13,5
Clamping range ØF (mm):	4 - 9
SW (mm):	24
Overall length, C (mm):	41
Thread length, D (mm):	9
Pieces / PU:	100
Caution:	Refer to Appendix T21 for the installation dimensions and torques
Colour delivered:	Silver grey (RAL 7001) Light grey (RAL 7035) Black (RAL 9005), UV-resistant
Material:	Body: Polyamide Seal: CR
Tests:	GGVS: TÜ.EGG.020-95
Protection rating:	IP 68 - 5 bar
Temperature range:	-20°C to +80°C

Product Management	Document: SKINTOP® STR	2 / 3
--------------------	------------------------	-------

U.I. Lapp GmbH	DATASHEET	 LAPP GROUP
	SKINTOP® STR	53015330 14.11.2013

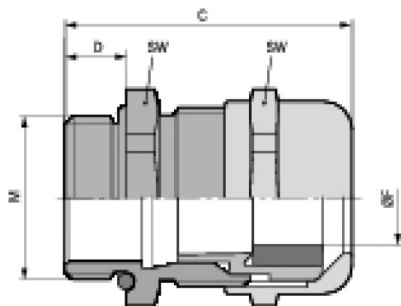

Product Management	Document: SKINTOP® STR	3 / 3
--------------------	------------------------	-------