

U.I. Lapp GmbH	<b>DATASHEET</b>	
	<b>SKINTOP® STR</b>	53018170 14.11.2013

 
High oil-resistance for maximum reliability  
 Permanent vibration protection  
 Optimum strain relief  
 Wide, variable clamping ranges  
 Various accessories (e.g. multiple sealing inserts)



Good chemical resistance



Mechanical resistance



Optimum strain relief



Temperature-resistant



Variety of approval certifications

### Application range

With reducing seal insert, to seal cables with smaller outer diameters.

### Design

PG connection thread

### Norm references / Approvals

UL File Nr. E79903

### Note

Refer to SKINTOP® PG accessories for suitable accessories  
 Counter nut to be used: SKINTOP® GMP-GL

### Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Product Management	Document: SKINTOP® STR	1 / 3
--------------------	------------------------	-------


U.I. Lapp GmbH	<b>DATASHEET</b>	
	<b>SKINTOP® STR</b>	<b>53018170</b> <b>14.11.2013</b>

**Technical Data**

Article designation / size:	STR 36
Clamping range ØF (mm):	17 - 26
SW (mm):	53
Overall length, C (mm):	66
Thread length, D (mm):	13
Pieces / PU:	10
Caution:	Refer to Appendix T21 for the installation dimensions and torques
Colour delivered:	Silver grey (RAL 7001) Light grey (RAL 7035) Black (RAL 9005), UV-resistant
Material:	Body: Polyamide Seal: CR
Tests:	GGVS: TÜ.EGG.020-95
Protection rating:	IP 68 - 5 bar
Temperature range:	-20°C to +80°C

Product Management	Document: SKINTOP® STR	2 / 3
--------------------	------------------------	-------

U.I. Lapp GmbH	<b>DATASHEET</b>	 <b>LAPP GROUP</b>
	<b>SKINTOP® STR</b>	53018170 14.11.2013

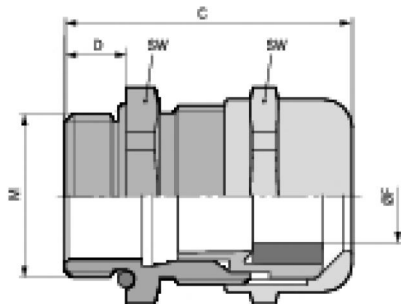

Product Management	Document: SKINTOP® STR	3 / 3
--------------------	------------------------	-------