





DATA SHEET	63106020
Through connectors 0,25 - 6 mm²	Valid from: 01.10.2007

Through connectors 0,25 - 6 mm²

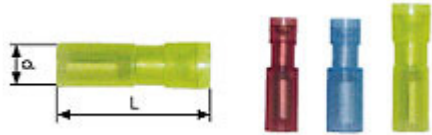

Technical data:

- electrolytic copper
- tin plated
- brazed barrel
- polyamid insulation
- easy-entry
- not for solid conductors

		Range m.m	for bullet	L	d
	L-RAA 15	0,5 - 1,5	4,0	24,0	3,6
	L-RBB 25	1,5 - 2,5	5,0	24,0	4,3
	L-RCC 6	4 - 6	5,0	27,0	5,7

For more safety on site all insulated connectors have an imprint that indicates the cross section of the respective connector. The crimping dies of the recommended tool emboss the cross section of the used die onto the connector insulation.

Easy-entry:

The insulation has an easy-entry device, which assures correct insertion of the conductor into the cable socket.

