

D-SUB HIGH DENSITY

Crimp body (without contacts) – For wire size AWG 22




RoHS compliant – CSA listed, File No.: LR 115000-1 – UL listed, File No.: E202784

DESCRIPTION


- For wire size **AWG 22** precision machined contacts
- Mounting style:
with through-hole \varnothing .118" / 3 mm
- Shell: Steel tin plated (brass tin plated or stainless steel available on request)

SOCKET CONNECTOR

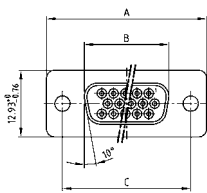


No. of pos.	A -0.76	B -0.25	C
15	31.19	16.46	25.00 $+0.12$
26	39.52	24.79	33.30 $+0.15$ -0.10
44	53.42	38.50	47.04 $+0.13$
62	69.70	54.96	63.50 $+0.13$
78	67.31	52.55	61.10 $+0.14$ -0.11


Mounting style: Through-hole

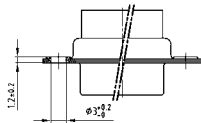

78 pos. = Dim. in (_ _)

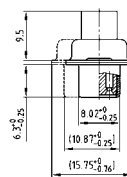


PLUG CONNECTOR

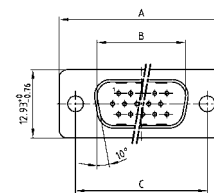


No. of pos.	A -0.76	B -0.25	C	D -0.3
15	31.19	16.79	25.00 $+0.12$	6.12
26	39.52	25.12	33.30 $+0.15$ -0.10	6.12
44	53.42	38.84	47.04 $+0.13$	5.99
62	69.70	55.30	63.50 $+0.13$	5.99
78	67.31	52.68	61.10 $+0.14$ -0.11	5.99

Mounting style: Through-hole

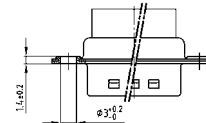

78 pos. = Dim. in (_ _)

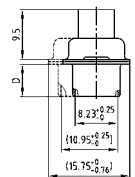

ORDER DATA

SOCKET CONNECTOR		
No. of pos.	Mounting style	Part Number
15	Through-hole	164X 11949 X
26	Through-hole	164X 11959 X
44	Through-hole	164X 11969 X
62	Through-hole	164X 11979 X
78	Through-hole	164X 11989 X

PLUG CONNECTOR		
No. of pos.	Mounting style	Part Number
15	Through-hole	163X 10169 X
26	Through-hole	163X 10179 X
44	Through-hole	163X 10189 X
62	Through-hole	163X 10199 X
78	Through-hole	163X 10209 X