

Datasheet

Item no. 1094725/ 1094726/ 1094727/ 1094728

V1_0717_01_en

Illuminated Metal Pushbutton



Signal lamp Key switch




Datasheet

Item no. 1094725/ 1094726/ 1094727/ 1094728

V1_0717_01_en



- ⊙ Φ 30mm Diameter
- ⊙ Lamp Type: Symbol+Bicolor light
- ⊙ LED Color: **R G Y O B W**
- ⊙ LED Voltage : 6V/12V/24V/36V/110V/220V
- ⊙ Rated Current: 2mA ~ 20mA
- ⊙ Crust Material: Stainless steel(S)
- ⊙ Terminal Type: Screw terminal
- ⊙ IP Degree: IP40,IK10
- ⊙ The illuminated symbol can be customized

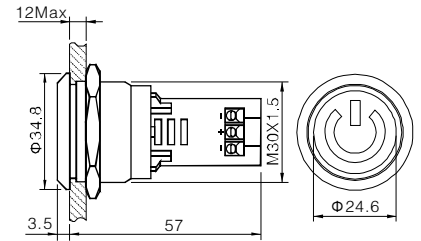

1094725 : Φ 30mm, Signal lamp, Red color 12V , "stand by" symbol

1094726 : Φ 30mm, Signal lamp, Green color 12V , "stand by" symbol

1094727 : Φ 30mm, Signal lamp, Blue color 12V , "stand by" symbol

1094728 : Φ 30mm, Signal lamp, White color 12V , "stand by" symbol

1094725 1094726 1094727 1094728		Material	Button	Stainless steel
			Body	Stainless steel
			Base	PBT
Panel Thickness	1 ~ 10mm			
Torque	1.6Nm			
Terminal Type	Screw terminal			
		RoHS	Yes	

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).
 All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.