

QuickFistClamps

One Piece Rubber Clamps

A CLAMPED TOOL IS A SAFE TOOL



All Quick Fist Clamps
are made from heavy duty
transportational grade rubber
NOT affected by hot
or cold climates
UV & water resistant

QUICK FIST CLAMPS & TIES LTD.

Scatterbrook Cottage, Carr Road, BURTON PIDSEA, East Yorkshire HU12 9DH
Tel: 01964 779590. Mobile: 07957 880099. Email: info@quickfistclamps.co.uk
www.quickfistclamps.co.uk VAT Reg. No. 153 8425 06
Company Registered in England No. 883644


Original QUICK FIST® Clamp

- Holds objects 25 to 54mm in diameter.
- Each clamp supports a safe working load of 11 kilos. 2 clamps support 23 kilos.
- Mounts easily with one 4mm bolt or screw.
- Mounting area 63 x 19mm
- Blister pack containing 2 clamps

Item No. 10010

Original QUICK FIST

Mounts: Hand tools like shovels, axes, flashlights and high lift jacks from 25 to 57mm diam.

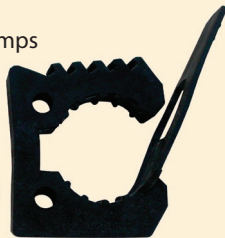

MINI QUICK FIST® Clamp

- Holds objects 16 to 32mm in diameter.
- Each clamp supports a safe working load of 11 kilos. 2 clamps support 23 kilos.
- Mounts easily with one 4mm bolt or screw.
- Mounting area 38 x 38mm
- Blister pack containing 2 clamps

Item No. 30050



MINI QUICK FIST

Mounts: Small tools and flashlights from 16 to 32mm diam.

GO-BETWEEN QUICK FIST® Clamp

- Holds tools and equipment from 44 to 73mm in diam.
- Each clamp supports a safe working load of 23 kilos, with a break-strength of 69kg.
- Mounts with two 6mm bolts or screws.
- Mounting area 25 x 89mm
- Poly bag with header containing 1 clamp.

Item No. 80010

GO-BETWEEN Quick Fist

*Mounts: Scaffolding poles,
battering rams, nozzles, pipes,
struts from 44 to 73mm diam.*



• Ideal for securing 50mm pike poles • Battering rams • Nozzles • Pipes • Struts



3" QUICK FIST® Clamp

- Holds objects 70 to 83mm in diameter.
- Each clamp supports a safe working load of 23 kilos.
- Mounts easily with one 6mm bolt or screw.
- Mounting area 113 x 32mm
- Clam shell with header containing 1 clamp

Item No. 50050



3" QUICK FIST

*Mounts: Fire Extinguishers
and Fuel Bottles from
70 to 83mm diam.*

SUPER QUICK FIST® Clamp

- Holds objects from 64 to 240mm in diam.
- Each clamp supports a safe working load of 23 kilos, 2 clamps support 45kg.
- Mounts with three 4mm bolts or screws.
- Mounting area 152 x 22mm
- Clam shell with header containing 1 clamp.

Item No. 20020



SUPER Quick Fist

Mounts: Cylinders from
64 to 240mm diam.




QUICK FIST clamps can hold tools and equipment from 16 to 432mm in diameter and work great on emergency vehicles, work trucks, off road vehicles, military, atvs and boats

QUICK FIST XL® Clamp

- Two separate 356mm straps hold round objects up to 381mm in diameter.
- Holds equipment measuring up to 711mm in linear distance.
- Each clamp supports a safe working load of 68 kilos, with a break-strength of 176 kg. 2 clamps support 176kg with a break-strength of 272kg.
- Each half of the clamp mounts with four 4mm bolts or screws.
- Mounting area 51 x 51mm
- Poly bag with header containing 2 pairs of clamps.

Item No. 60060

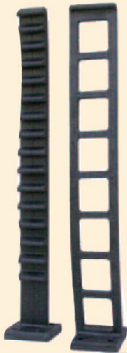

QUICK FIST XL

Mounts: Jerry cans, acetylene tanks, coolers up to 381mm in diam or 711mm in linear measurement.



Clamps are made from (EPDM Ethylene-propylene-non-conjugated diene rubber), the same material as tyres. As such they are extremely heat, cold, water (sea or fresh) and UV resistant.

QUICK FIST® LONG ARM Clamp

Especially good for mounting items that are coiled, equipment with a handle and multiple tools.

- Holds objects from 13 to 114mm in diameter.
- Each clamp supports a safe working load of 23kg with a break-strength of 55kg.
- Mounts easily with two 6mm bolts or wood or sheet metal screws, plus washers.
- Blister pack containing 2 clamps.

Item No. 40010



Great for mounting things with a handle



Long Arm clamps easily hold multiple tools




QUICK FIST LONG ARM CLAMP

Mounts: Items that coil, high lift jacks, multiple tools from 13 to 114mm diam.

QUICK FIST® MICRO CABLE CLAMPS

- Holds any object, pipe or cable from 15 to 20mm diameter safely, securely and accessibly.
- Mounts easily with either adhesive fixing or a bolt or screw, easily re-opened.
- Polybag pack contains 5 cable clamps.
- Ideal when cable runs need to be accessed, resistant to water (fresh and sea), UV, heat and cold, just wash clean and open

Item No. 30032

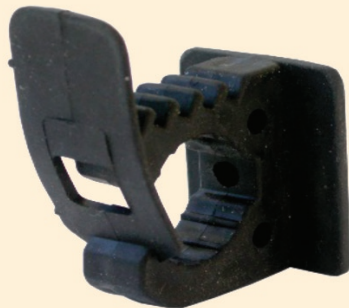

QUICK FIST® RUBBER TIE DOWN BELT (INDIVIDUAL BELTS)

Significantly Stronger, Wider, Safer and more weather resistant than Bungee Cord!

NEW



965 x 38 x 6mm Belt that Secures Equipment

- Not affected by Hot or Cold Climates
- Water (fresh or sea) and UV Resistant
- Two Belts can be “Buttoned” together to almost double its length with the connector included in every pack.
- Two ways to install, choose your fixing, hook or bolt-on post
- For use on work and emergency vehicles, off road and military trucks, ATVs and boats



Item No. 11050



One 965mm Belt



Two Mounting Posts (screw or bolt in place)
(Approximate mounting area 38 x 19mm)



One Connector

Item No. 11060



One 965mm Belt



Two Hooks (“buttons” to any hole on belt)



One Connector

QUICK FIST® RUBBER TIE DOWN BELT (AS A KIT)


TIP - warm belt with a hairdrier for easier insertion of the hooks or connections



965 x 38 x 6mm Belt that Secures Equipment

- Not affected by Hot or Cold Climates
- Water (fresh or sea) and UV Resistant
- Two Belts can be "Buttoned" together to almost double its length with the enclosed connector.
- Two ways to install (Both are included): With hooks for existing attachment points or with Bolt-on Mounting Posts.
- For use on work and emergency vehicles, off road and military trucks, ATVs and boats

Item No. 11075

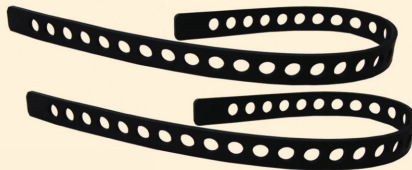

2 QUICK FIST TIE DOWN BELTS



ONE CONNECTOR



4 MOUNTING POSTS



4 HOOKS



NEW

QUICK FIST® Roll Bar Tool Mounts

*Fits all roll bars from
25 to 64mm in diameter*

Use with the Original QUICK FIST clamp No. 10010 (sold separately) to mount a flashlight, shovel axe, high lift jack or other tools from 25 to 57mm in diameter to a roll bar.


Use with the SUPER QUICK FIST clamp No. 20020 (sold separately) to mount a fire extinguisher, air tank, nitrous tank or other tools from 64 to 241mm in diameter to a roll bar.

The safe working load for two QUICK FIST roll bar mounts on roll bars less than 38mm in diameter is 25kg. Roll bars 38mm or larger in diameter the safe working load is 50kg.

Contents:

- 2 each Delrin® Roll Bar Mounts
- 2 each 14x100mm Stainless Steel Hose Clamps.
- 2 each 38x175mm Neoprene Rubber Strips
- 6 sets $\frac{7}{8}$ " x No. 10 Stainless Steel Bolts, washers and Nuts.


Item No. 90050

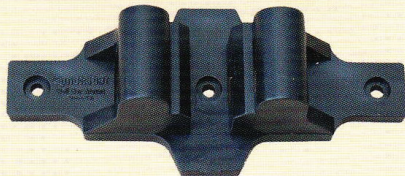

Roll Bar Tool Mount 90050 with two Original QUICK FIST clamps No. 10010 to mount a flashlight, shovel, axe, high lift jack or other tools from 25 to 57mm in diameter to a roll bar.

Item No. 90015


AS A KIT

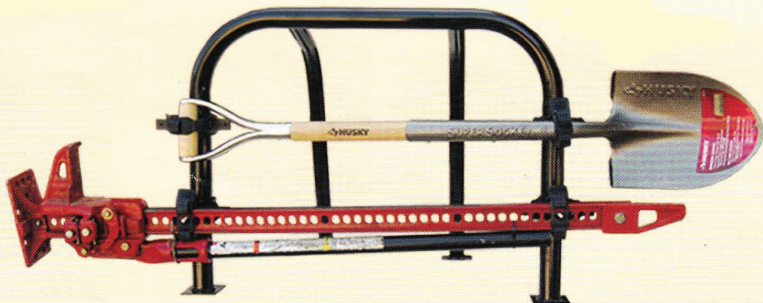

Roll Bar Tool Mount 90050 with two SUPER QUICK FIST clamps No. 20020 to mount a fire extinguisher, air tank, nitrous tank or other tools from 64 to 241mm in diameter to a roll bar.

Item No. 90020

AS A KIT

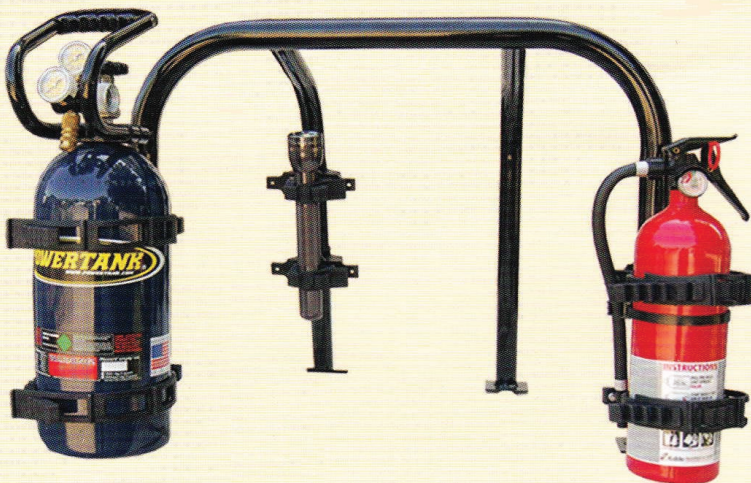

QUICK FIST® MOUNTING KIT

8 of our Top Selling Clamps (3 sizes)
in One Convenient, Money Saving Package

Contains

4 ORIGINAL QUICK FIST clamps
2 MINI QUICK FIST clamps
and 2 SUPER QUICK FIST clamps

ITEM NO. 90010



DEALER/OEM ENQUIRIES WELCOME

We import direct from the US manufacturer all the retail products shown on these pages. Certain of the products can be bought in bulk as single items, suitable for larger volume usage (see table on right)
Please see the TRADE side of our website or contact direct for a Price List
info@quickfistclamps.co.uk

	retail code	Bulk/Trade code
	10010	T10012
	20020	T20022
	30032	T30032
	30050	T30052
	40010	T40012
	43211	T43210
	50050	T50052
	60060	T60022
	80010	T80011

NEW

QUICK FIST® WEAPON CLAMP

Universal Vehicle Mount for Rifles, Shotguns or ARs




- Securely mounts weapon vertically or horizontally in any vehicle
- Works with or without telescopic sight.
- Quick Release.
- Safe working load is 45kgs.
- One clamp secures the stock while the other holds either the forend or barrel

Item No. 01887

Quick Fist Clamps are made of heavy duty synthetic rubber which is resistant to most chemicals, UV, and operates in extreme HOT and COLD temperatures



Butt and Forend Mount

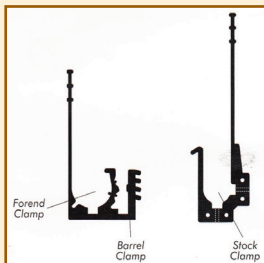

Butt and Barrel Mount



Butt and Forend Mount

NEW

ENGINEERS' ASSESSMENT KIT

Contains a sample of all* the current types of clamps, everything you need to enable assessment of their suitability and fit.



Installation Instructions for the individual clamps can be downloaded from our website – www.quickfistclamps.co.uk Quick Fist clamps are made from EPDM (Ethylene-propylene-non-conjugated diene rubber) so please use washers as directed and avoid over-tightening nuts/screws.

Item No. 90080

Contains:-

10010 - 1 Quick Fist ORIGINAL (with washer)
10075 - 1 Quick Fist Tie Down Belt, 1 Post,
1 Hook, 1 Connector
20020 - 1 Quick Fist SUPER
30050 - 1 Quick Fists MINI
40010 - 1 Quick Fist LONG ARM

50050 - 1 Quick Fist 3"
60060 - 1 pair Quick Fist XL
80010 - 1 Quick Fist GO-BETWEEN
90050 - 1 Quick Fist Roll Bar Clamp Set

**Gun Clamp excluded*

ABOUT US

We import directly from End of the Road Inc. Nashville, Tennessee who have been making clamps for mounting tools and equipment on vehicles since 2003.

The owner, inventor and founder, Don, had been a business colleague since the early 90's and here in the UK we will be keeping extensive stocks of the range of clamps for immediate despatch.

The invention of QUICK FIST CLAMPS came out of a fortunate happening. On buying a \$10.00 spade, Don found that there was nothing on the market which could easily and inexpensively hold the spade to the outside of his vehicle; making it secure yet readily available. In the end he paid nearly \$80.00 for something which was suitable though not ideal.

The company started out with the one clamp, THE ORIGINAL, to hold shovels, axes and 'D' cell torches, and since then have added additional sizes to meet a variety of applications

Many of the original clamps are still mounted on the vehicles they where installed years ago.

Originally designed for the adventure/leisure fraternity, they have become a major supplier to the Fire, Police and Emergency Services in the US.

All the products are made in the USA and have been tested against NFPA Standard 1901

Dealer and OEM enquiries always Welcome - see our Engineers' Trial Kit

Chris M. Brown

QUICK FIST CLAMPS and NFPA Standard 1901

Southwest Research Institute (www.swri.edu) has tested the QUICK FIST clamps and all products meet the 9-G force standard when the weight of the item being held by the clamp does not exceed the following loads.

Item	Product	Non crew areas Safe Working Load*			Crew areas Max. weight		
		One Clamp	Two Clamps	Three Clamps	One Clamp	Two Clamps	Three Clamps
30050	MINI QUICK FIST Clamp	25	25		5	10	
10010	ORIGINAL QUICK FIST Clamp	25	50		5	10	
20020	SUPER QUICK FIST Clamp	50	100		15	30	
40040	Long Arm QUICK FIST Clamp	50	100		15	30	
50050	NOZZLE QUICK FIST Clamp	50	100		15	30	
60060	QUICK FIST XL Clamp	150	300		50	100	
80010	QUICK FIST Go-Between Clamp	50	100		15	30	

*50% of the break strength

QuickFistClamps

One Piece Rubber Clamps

**A CLAMPED TOOL
IS A SAFE TOOL**



All Quick Fist Clamps
are made from heavy duty
transportational grade rubber
NOT affected by hot or cold
climates UV resistant

QUICK FIST CLAMPS & TIES LTD.

Scatterbrook Cottage, Carr Road, BURTON PIDSEA, East Yorkshire HU12 9DH
Tel: 01964 779590. Mobile: 07957 880099. Email: info@quickfistclamps.co.uk
www.quickfistclamps.co.uk VAT Reg. No. 153 8425 06
Company Registered in England No. 883644