


® CAT 6 Connection module for Twisted Pair Cables

DN-93903

4016032267133

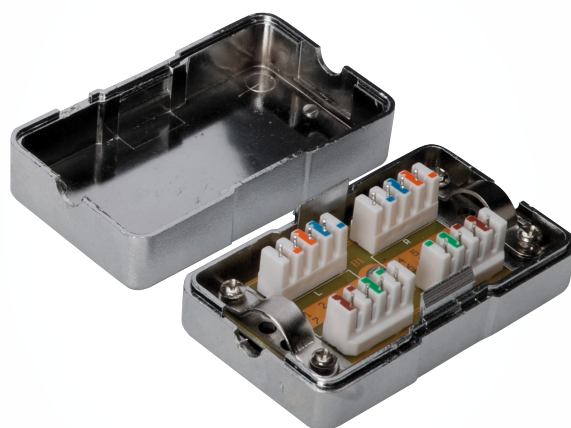

Best performance and link quality for your network.

The DIGITUS® Connection module is for the purpose of connecting or extension of Twisted Pair Cables.

- Material enclosure: ABS non halogen, UL 94 V0
- Material surface: Copper with shining nickel
- Connection over LSA strips
- Shielded
- Integrated strain relief
- LSA EIA/TIA 568 A & B
- Cable entry: up to 6,8mm
- Diameter Cu-Conductor: AWG (26/1 ... 22/1)
- Temperature range: -40 °C ... +80 °C
- Current carrying capacity: 1A at 50 °C
- Material IDC Terminal: Phosphor bronze with 50µ tin plated over 60µ nickel plated
- Material PCB: FR4, 1.2 mm thickness
- Workable with 110- and KRONE LSA punch down tools

