
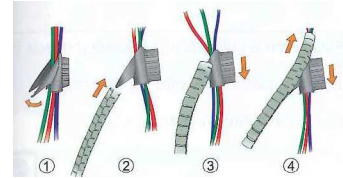
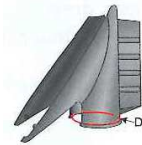


**SPLIT WRAPPING BAND**

**INSTALLATION TOOL FOR SPLIT WRAPPING BAND**

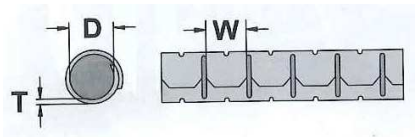

Split wrapping band					Installation Tool		
B/N	D	T	W	Wrapping Range	B/N	D	Material: P.P. Color: Black
1091103 / 1166158	8	0.8	9	10	1091124	8	
1091104 / 1166159	15	0.8	13	16	1091125	15	
1091105 / 1166160	20	0.9	15	22	1091126	20	
1091106 / 1166161	25	1.3	18	27	1091127	25	
1091107 / 1166162	32	1.3	23	35	1091128	32	

Unit: mm

- Material: PP
- Color: Black
- Operating Temperature: 0 to 80°C
- Storage Temperature: 25 to 30 °C
- Application:
  1. Cut into suitable length, and use the special tool to wrap band the wire easily.
  2. Hold the topside of wire with installation tool, and draw down to wrap the wire immediately by easy and fast.
  3. This wire band designed to be easy off and re-usable, the tensile power will be remain after every wrap and peel.
- Tensile power: Easily applied and safety to protect cables and wire bundles from damage and electric harmless