

You might also like...

Q7<sub>xr</sub>



V3<sub>r</sub>



Product Overview

 


We provide 5 years limited warranty, which means that either we or our dealers will exchange any defective part of the lamp or the complete lamp within the warranty period. Warranty is invalid if it is clearly visible that damage is caused by abuse or mistreatment not following procedures of proper care and maintenance. Batteries are not part of the warranty.

Register your product at [www.suprabeam.com](http://www.suprabeam.com) and get the latest information and news by e-mail

This product is tested with Energizer® batteries. We highly recommend to use Premium type batteries only to ensure high quality light output and long lighting time. We can not guarantee the light data if using battery types of lower quality

*To protect the environment, this product is compatible with rechargeable batteries 1.2-1.5V (not Li-Ion 3.7V)*



Steiner A/S  
P.O. Pedersens Vej 14A · DK-8200 Aarhus N  
Phone: +45 87 52 52 12  
Fax: +45 87 52 52 15

Contact: [info@suprabeam.com](mailto:info@suprabeam.com) · [www.suprabeam.com](http://www.suprabeam.com)

Warranty and Warnings

 **suprabeam®**



Q1



## Changing Battery

 


## Operating




Manual

## Rotating Hyperfocus™




Thank you for purchasing our Suprabeam Q1. It combines micro size and extreme power making it ideal for precise and professional use.

For more info:

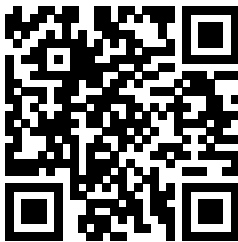

## Q1

 

Hours:	< 8 h
Battery:	2 x AAA Alkaline or NiMH
Beam angle:	Variable_Spot 5°_Flood 65°
Beam Distance:	70 m
Case Material	Anodized Aluminium
Weight:	56 g
Temp.	-20°C to + 50°C
IP Rating	x4
LED Type:	1 CREE LED Chip

Electronic Control:

High:	100 Lumens
Low:	20 Lumens

Technical Data