

PERFECT SOUND.  
PERFECT PICTURES.



MKE 600

 **SENNHEISER**  
The Pursuit of Perfect Sound



## Your Reliable Companion for Every Shoot: The New MKE 600

**Wherever** the magic moment occurs: The success of your work depends on achieving the perfect interplay of image and sound – and under the most difficult conditions. No matter if you're shooting outdoors in the city or indoors with poor acoustics: Sennheiser has the perfect solution for first-class video sound.



**The MKE 600**, the new condenser microphone with outstanding directivity was developed for video journalists who require high-quality audio and easy to use equipment. When you need to switch locations and change camera settings quickly, this new shotgun microphone is your ideal companion for demanding shoots.



# Perfect sound without background noise.

**The MKE 600's main strength** is its rich sound with its excellent reproduction of low frequencies. This allows you to record speech easily and ensures high intelligibility. Its high directivity means that even audio that was recorded from a distance sounds as if the speaker had been much closer to the microphone. Furthermore, lateral interference noise is reliably suppressed. The low-cut filter reduces handling noise and wind noise. With the MKE 600, you can enjoy perfect sound without the noise.



**No phantom power required.** Since not all video cameras are equipped to supply phantom power for a microphone, the MKE 600 can also be operated using standard AA batteries. Battery power can be switched on easily and then switched off again when the camera is no longer in use – this keeps the battery from discharging too rapidly. An LED on the battery switch lets you know when the batteries are running low while there is still a reserve of approximately eight hours – enough time to finish your shoot successfully.

# MKE 600

Your reliable companion for demanding shoots.



**The MKE 600** is a professional shotgun condenser microphone for video journalists and is used at locations where high-quality audio and simple operation are required. Bothersome lateral interference noise is suppressed and the microphone's low-cut filter ensures the additional attenuation of handling and wind noises. The MKE 600, along with its professional accessories, make up a sophisticated system for flawless recordings.



### Features

- Easy to use thanks to plug and play technology
- Maximum attenuation of background noise for clear, rich sound
- Low-cut filter for minimizing wind noise
- P48 phantom power or battery power
- Battery switch with a Low Batt indicator
- Rugged, all-metal housing
- Made in Germany

### Delivery includes

- MKE 600:  
Shotgun microphone
- MZS 600:  
Shock mount
- MZW 600:  
Foam windshield
- User manual

## Accessories.

The MKE 600 is versatile. Its additional accessories provide you with even greater flexibility.




### MZH 600

Fur windshield. Light and weather-proof for optimal wind noise attenuation.



**MZW 600**  
Foam windshield  
(included).

---

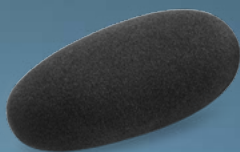

**KA 600**  
Microphone adapter cable for audio-in.

---



**MZS 600**  
Shock mount  
(included).

---



**MZQ 600**  
Stand adapter.



# Technical data

---

**Pick-up pattern**

**Frequency response**

**Sensitivity with P48**

**Sensitivity with battery power**

**Maximum sound pressure level with P48**

**Maximum sound pressure level with battery power**

**Equivalent noise level with P48**

**Equivalent noise level with battery power**

**Power supply**

**Power consumption with P48**

**Operating time with battery**

**Low Batt display**

**Diameter**

**Length**

**Weight**

**Operating temperature**

## MKE 600

---

Super-cardioid/lobar

40 Hz to 20 kHz

21 mV/Pa

19 mV/Pa

132 dB SPL

126 dB SPL

15 dB (A)

16 dB (A)

48 V  $\pm$  4 V (P48, IEC 61938) via XLR-3  
or disposable/rechargeable batteries (AA 1.5 V/1.2 V)

4.4 mA

Approx. 150 hours

< 1.05 V;  
approx. 8 hours of operating time remaining after the first display

20 mm

256 mm

128 g (without battery)

-10 °C to +60 °C



Sennheiser electronic GmbH & Co. KG

Am Labor 1, 30900 Wedemark, Germany

Phone +49 5130 600-0

Fax +49 5130 600-300

[www.sennheiser.com](http://www.sennheiser.com)