

# Audio cable

## cinch coaxial cable for dynamic audio sound

When you value good sound, you will need the right audio cable. Because electromagnetic interactions can easily affect sensitive audio signals, multiple shielded cables assist subtle pulses to be undistorted up to the amplifier. Pure materials, and precise workmanship render additional support.

- 50 Ω defined wave impedance
- pure copper conductor and 2-way shielding for clear signal quality
- 24-Karat gold plated contacts for minimum transfer resistances

### Specifications

#### Connections

Plug material:	triple-coated PVC / ABS
Contact material:	24-Karat gold plated
Shielding:	yes
Port 1, type:	RCA plug (RCA)
Connector 1, connector length (mm):	39.8
Connector 1, connector width (mm):	14.0
Connector 1, connector height (mm):	14.0
Port 2, type:	RCA plug (RCA)
Connector 2, connector length (mm):	39.8
Connector 2, connector width (mm):	14.0
Connector 2, connector height (mm):	14.0

#### cable


Type:	Round cable
Length (m):	0.5   1   2   3   5   7.5   10   15   20
Inner conductor material:	OFC (Oxygen free copper)
Inner conductor diameter (mm):	25 x 0.120
AWG:	23
Number of shieldings:	2 x
Type of 1st shielding	Aluminium foil
Type of 2nd shielding	Copper braid 96 wires x 0.12 mm cross section
Outer sheath material:	highly elastic PVC
Outer sheath diameter (mm):	6.0
Kink protection:	on both sides

#### Signal transmission

Transmission modes:	analog and digital audio signals
max. Bandwidth (MHz):	10.0
Capacitance (pF):	155
Characteristic impedance (Ω):	50

#### General

Operating temperature from / to (°C):	-10 / +80
Warranty (years):	10

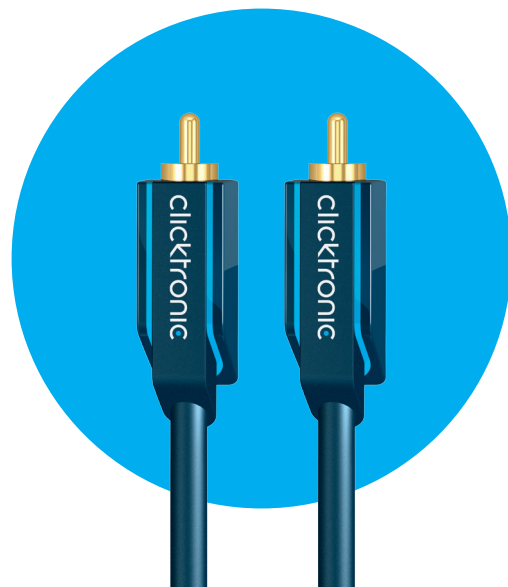


RCA plug (RCA)



RCA plug (RCA)



#### Cross section

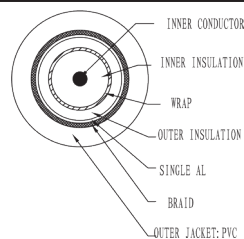










#### Wiring diagram



 <b>Designed in Germany</b>	 <b>10 Years Warranty</b>	 <b>OFC</b> 99,99% Oxygen Free Copper	 <b>24 Carat Gold</b> Anti Resistance Connections	 <b>2x</b> Cable Shielding
--	--	---	---	--

## Audio cable

cinch coaxial cable for dynamic audio sound

Article no.	Cable lengths (m)	Packaging dimensions (mm)	Weight (kg)	Figure	EAN Code
70442	0.50	Single carton: 185 x 80 x 25 Master carton (40 pcs.): 400 x 295 x 235	Single carton: XX Master carton: XX		4 040849 704420
70443	1.00	Single carton: 185 x 80 x 25 Master carton (40 pcs.): 400 x 295 x 235	Single carton: XX Master carton: XX		4 040849 704437
70445	2.00	Single carton: 185 x 80 x 25 Master carton (40 pcs.): 400 x 295 x 235	Single carton: XX Master carton: XX		4 040849 704451
70446	3.00	Single carton: 185 x 180 x 40 Master carton (24 pcs.): 400 x 285 x 435	Single carton: XX Master carton: XX		4 040849 704468
70447	5.00	Single carton: 185 x 180 x 40 Master carton (24 pcs.): 400 x 285 x 435	Single carton: XX Master carton: XX		4 040849 704475
70448	7.50	Single carton: 185 x 180 x 55 Master carton (20 pcs.): 400 x 310 x 435	Single carton: XX Master carton: XX		4 040849 704482
70449	10.0	Single carton: 185 x 180 x 55 Master carton (20 pcs.): 400 x 310 x 435	Single carton: XX Master carton: XX		4 040849 704499
70451	15.00	Single carton: 185 x 180 x 70 Master carton (16 pcs.): 400 x 315 x 435	Single carton: XX Master carton: XX		4 040849 704512
70452	20.00	Single carton: 185 x 180 x 70 Master carton (16 pcs.): 400 x 315 x 435	Single carton: XX Master carton: XX		4 040849 704529

TARIC Code: 85444290900

At Clicktronic® cables are designated as standard HDMI™ cables above a length of 7.5 meters, according to the test criteria, even if they originally are designed as High Speed HDMI™ cables and mostly show a significant power increase over long distances.

All company and product names are trademarks of their respective owners. All rights reserved. HDMI™ is a registered trademark of HDMI Licensing L.L.C.

The content may differ from those shown. We reserve the right for printing errors and changes to product packaging or documentation. Clicktronic®, Pilmannstraße 12, D-38112 Braunschweig/Germany