




# Safety Instructions



0, 1, 6, 8, 11, 12, 15,  
22, 23, 25, 28

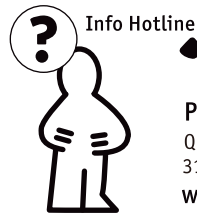

Info Hotline **+49 (0) 5041 998 389**

Mon. - Do. 7<sup>00</sup> - 20<sup>00</sup>

Fr. 7<sup>00</sup> - 17<sup>00</sup>

**Paulmann Licht GmbH**







Quezinger Feld 2  
31832 Springe / Germany  
[www.paulmann.com](http://www.paulmann.com)

Art.-Nr.:

**704.80**

**704.81**

(+MA 173)  
PMK 02/14

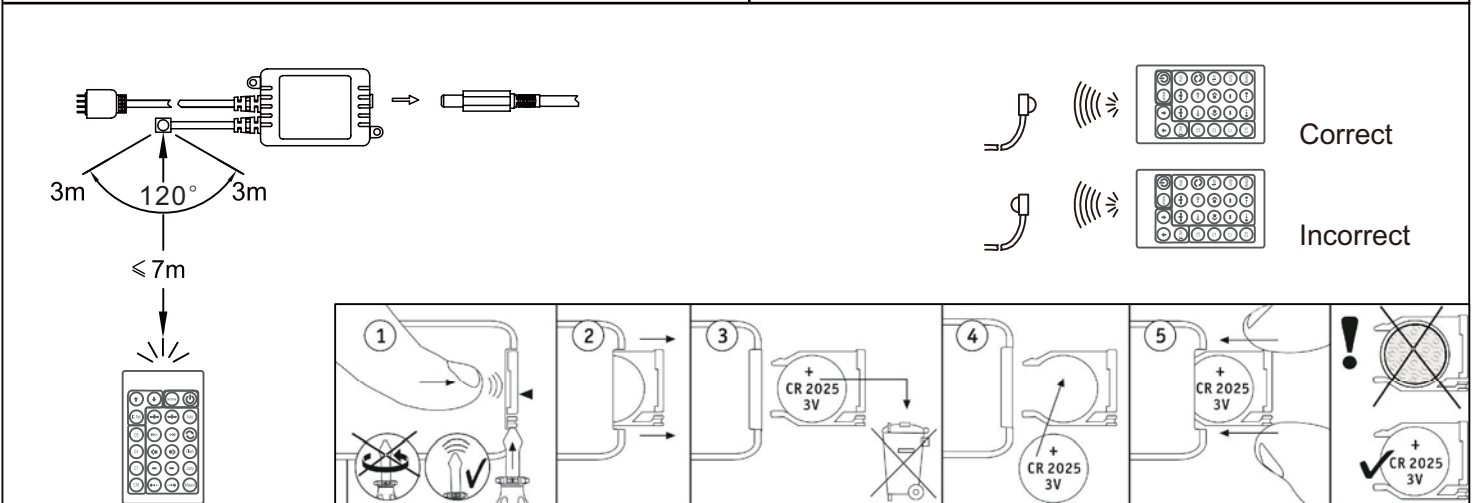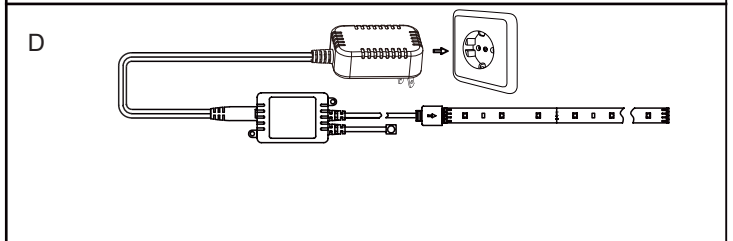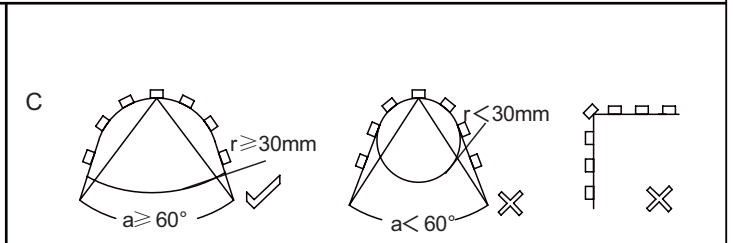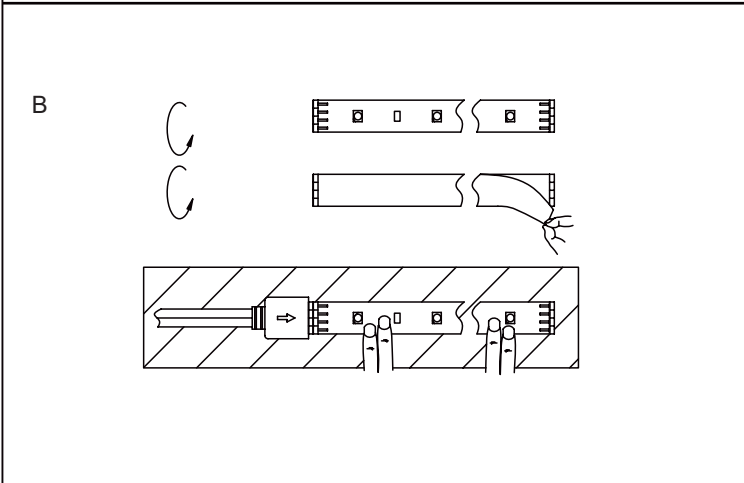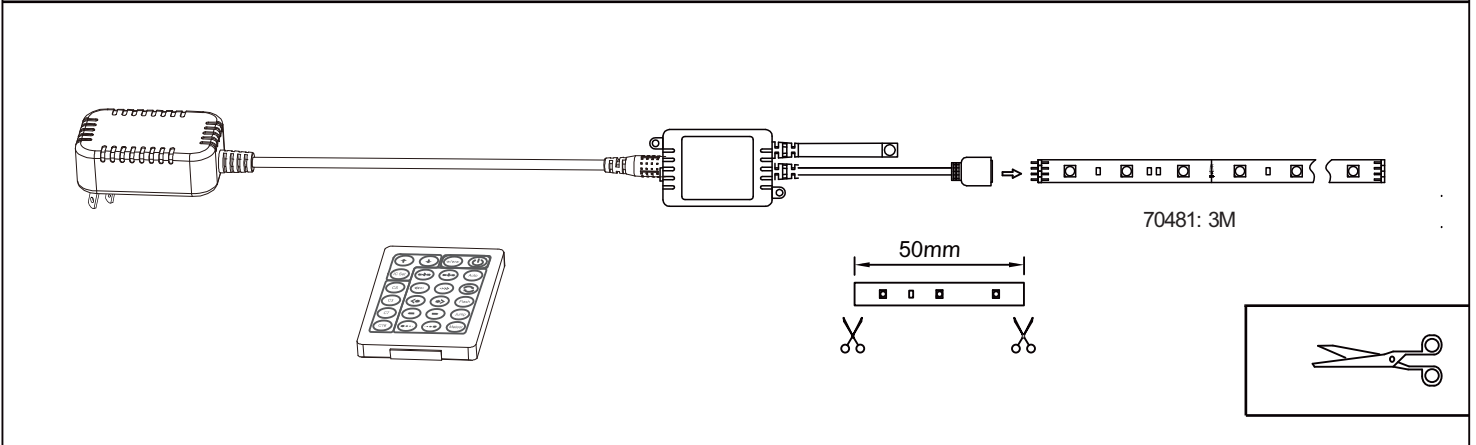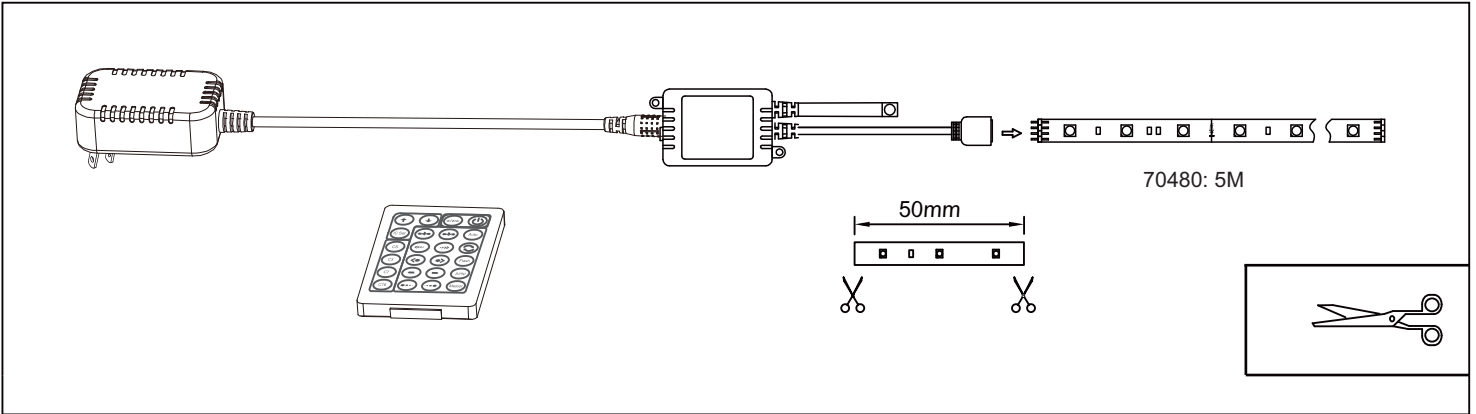



- |  |   |  |   |
|--|---|--|---|
|  | Light increases when in static mode, speed increases when in dynamic mode and IC number increases when in IC setting mode |  | Light decrease when in static mode, speed decrease when in dynamic mode and IC number decreases when in IC setting mode |
|  | WWW shift key   |  | ON/OFF key  |
|  | IC number setting   |  | flow to two terminals from centre (CS,C3,C7,C16)  |
|  | flow to centre from two terminals (CS,C3,C7,C16)  |  | Auto-cycle mode   |
|  | eight-color choice key in static model  |  | Trail into left ċ CS,C3,C7,C16 Ď  |
|  | Trail into right ċ CS,C3,C7,C16 Ď   |  | Trail from two directions in turn   |
|  | three-color choice key in static model  |  | Horse race to left direction (CS,C3,C7,C16)   |
|  | Horse race to right direction (CS,C3,C7,C16)  |  | Flash function key (CS,C3,C7,C16)   |
|  | seven-color choice key in static model  |  | spread to left (CS,C3,C7,C16)   |
|  | spread to right (CS,C3,C7,C16)  |  | Jump efficient key (CS,C3,C7,C16)   |
|  | sixteen-color choice key in static model  |  | Queued color running to left with a tag (CS,C3,C7,C16)  |
|  | Queued color running to right with a tag (CS,C3,C7,C16)   |  | Queued color running with a tag from two directions in turn   |

On / Off

Dimm

Length setting

Speed

Light effects

„Flow“  
 „Trail“  
 „Horse Race“  
 „Spread“  
 „Queued“

Choose color — CS  
3 color — C3  
7 color — C7  
16 color — C16

Mix of all effects

Mix of >>>

Fade

Color jump

Mix of <<<