



**BR-2/3AG**

DIMENSIONS (MM)

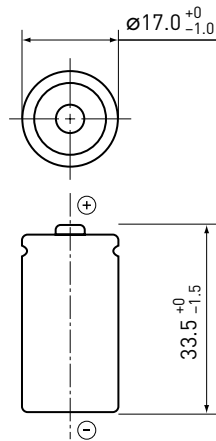


**BR-A**

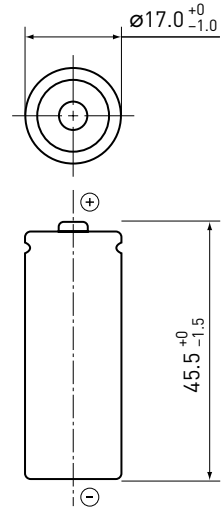


Model number	BR-2/3AG
Nominal voltage (V)	3
Nominal capacity (mAh)	1,450
Diameter (mm)	17.0
Total height (mm)	33.5
Discharging temperature range (°C)	-40 to +85
Weight (g)	13.5

Model number	BR-A
Nominal voltage (V)	3
Nominal capacity (mAh)	1,800
Diameter (mm)	17.0
Total height (mm)	45.5
Discharging temperature range (°C)	-40 to +85
Weight (g)	18.0


**DISCHARGE TEMPERATURE CHARACTERISTICS**

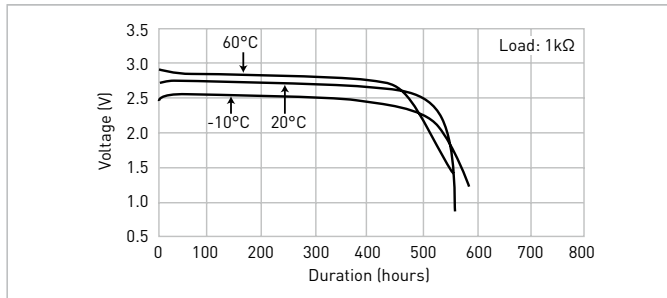


**DISCHARGE TEMPERATURE CHARACTERISTICS**

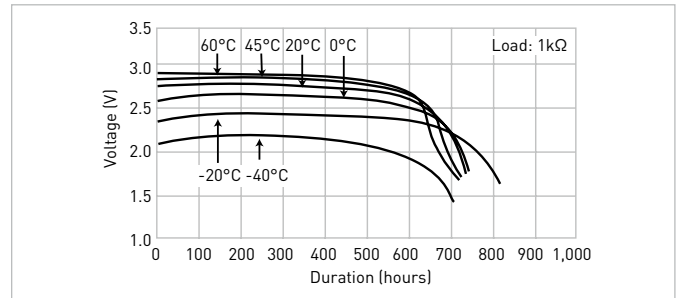

**OPERATING VOLTAGE VS. DISCHARGE CURRENT\*1**

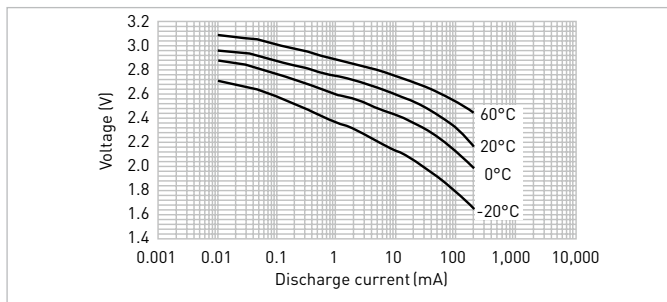

**OPERATING VOLTAGE VS. DISCHARGE CURRENT\*1**

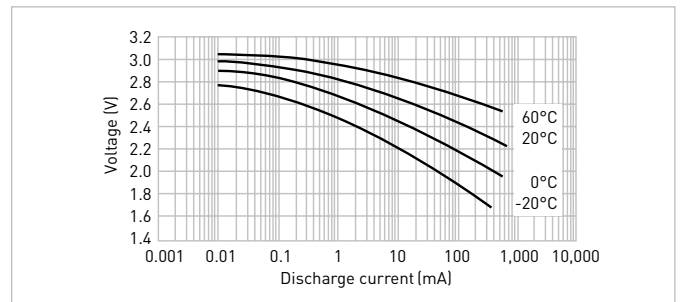

The data in this document are for descriptive purposes only and are not intended to make or imply any guarantee or warranty.

\*1 Voltage at 50% discharge depth.