

ONYX M+7

ONYX Copilot M | LED accessories for vehicle interior



Areas of application


- Vehicle interior
- Reading light

Product benefits

- 2 year guarantee
- Comfortable warm and glare-free light
- Individual adjustment thanks to bendable neck
- Pleasantly soft, easy to grip and dirt resistant surface
- Luminaire can be switched on/off and remain connected permanently

Product features

- Reading luminaire with LED lamp for vehicle interior
- Supply voltage: 12 V and 24 V
- Available with color temperature: 3,200 K
- Luminous flux: 20 lm/m
- Lifetime (LED): up to 20,000 hours
- Mounting in cigarette lighter
- Plug standard according to ISO 4165 and SAE J563

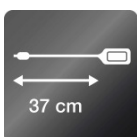


Technical data

Electrical data

Power input	0.5 W
Power input tolerance	±10 %

Dimensions & weight

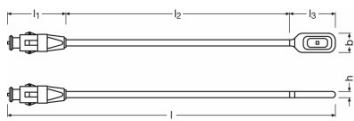

Length	473.0 mm
--------	----------

Product datasheet

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4052899077270	ONYX M+7	Folding carton box 1	110 mm x 35 mm x 290 mm	1.12 dm ³	139.50 g
4052899077287	ONYX M+7	Shipping carton box 4	149 mm x 118 mm x 302 mm	5.31 dm ³	828.00 g
4052899077294	ONYX M+7	Shipping carton box 32	- x - x -		

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

References / Links

Guarantee terms are available at

▶ www.osram.com/am-guarantee

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.