


MICROPHONE CARTRIDGE

CERAMIC Type

Item no. CC-35




Unit: mm
(Tolerance: $\pm 3\%$)

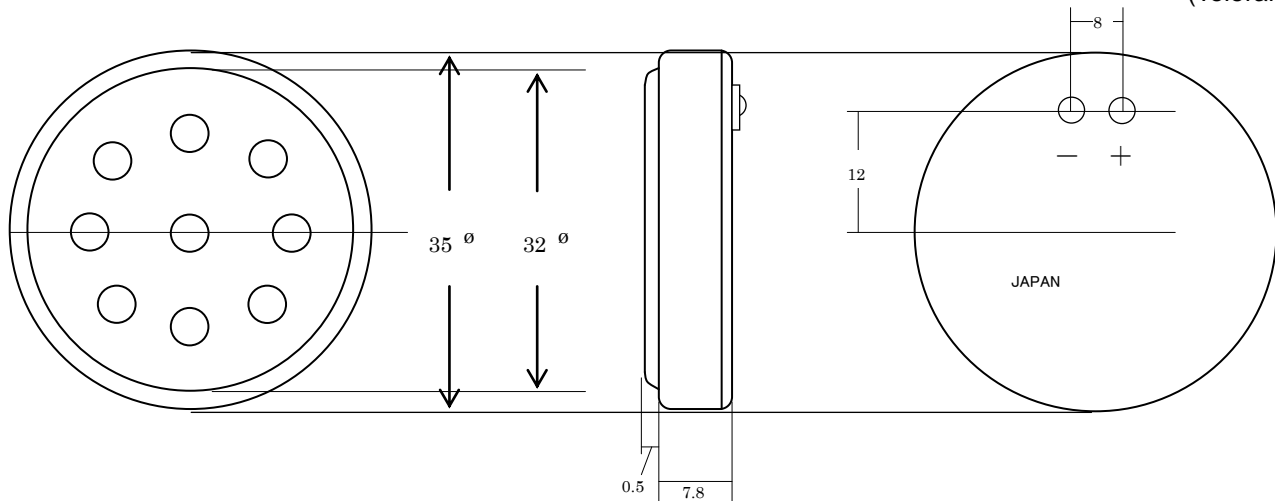

Specification:

Sensitivity : -55 db at 1 kHz
Response : 100Hz — 10kHz
Capacity : 750 pF at 1 kHz 25°C
Directivity Non-directional
Impedance : 230 k Ω
Material : Aluminum
Weight : 5 g
Operating Temperature : $-20^{\circ}\text{C} \sim +80^{\circ}\text{C}$

Typical frequency response curve:

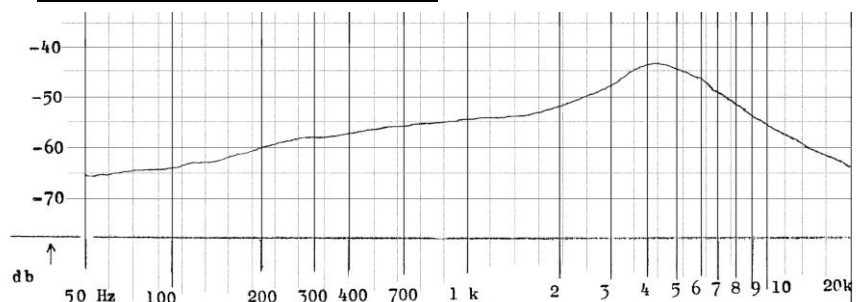

Distributed by Conrad Electronic SE

This data sheet is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This data represent the technical status at the time of printing. Changes in technology and equipment reserved.

© Copyright 2013 by Conrad Electronic SE.