
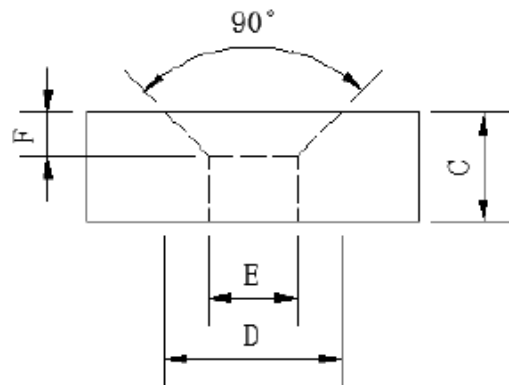
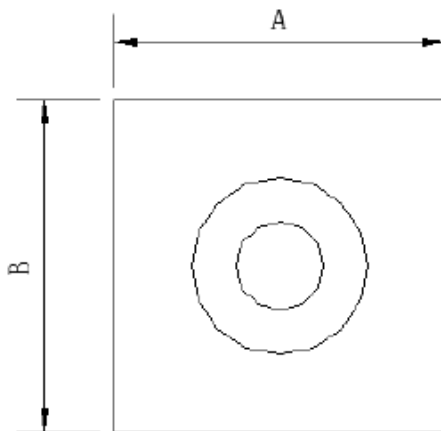


Data Sheet

NdFeB-Magnet Rectangular N35 w/ Countersink Hole (2 PCS Pair)

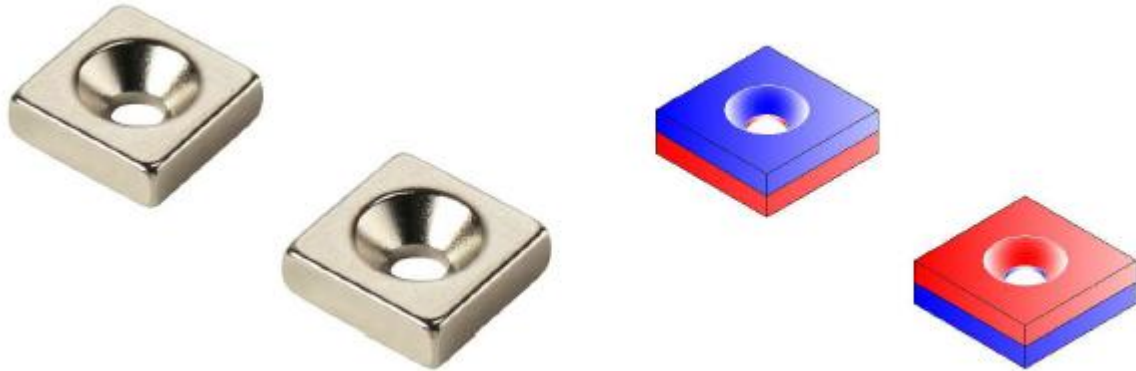

Data Sheet

Dimension

Item no.	Length (A)	Width (B)	Height (C)	Countersink	Head Ø (D)	Base Screw Ø (E)	Head Height (F)
1218980 / 1568111	10mm	10mm	3mm	M3	6mm	3mm	1.5mm
1218981 / 1572494	10mm	10mm	5mm	M3	6mm	3mm	1.5mm
1218982 / 1568112	15mm	15mm	3mm	M4	8mm	4mm	2mm
1218983 / 1568113	15mm	15mm	5mm	M4	8mm	4mm	2mm
1218984 / 1572495	20mm	12mm	3mm	M4	8mm	4mm	2mm
1218985 / 1568114	20mm	12mm	5mm	M4	8mm	4mm	2mm
1218986	20mm	20mm	3mm	M4	8mm	4mm	2mm
1218987 / 1572496	20mm	20mm	5mm	M4	8mm	4mm	2mm
1218988 / 1565436	25mm	25mm	3mm	M5	10mm	5mm	2.5mm
1218989 / 1568115	25mm	25mm	5mm	M5	10mm	5mm	2.5mm
1218990 / 1568116	30mm	15mm	3mm	M5	10mm	5mm	2.5mm
1218991	30mm	15mm	5mm	M5	10mm	5mm	2.5mm

Data Sheet

1218992 / 1568117	30mm	20mm	3mm	M5	10mm	5mm	2.5mm
1218993 / 1568118	30mm	20mm	5mm	M5	10mm	5mm	2.5mm

GradeN35
 Remanence Br 11.8 to 12.4 kGs
 Coercivity bHc ≥ 10.9 kOe
 Intrinsic Coercivity iHc ≥ 12 kOe
 Max Energy Product BHmax33 to 37 MGOe
 Operating Temperaturemax. 80°C
 Tolerance ± 0.1 mm