

ENERGIZER E96


AAAA



Specifications


Classification:	Alkaline
Chemical System:	Zinc-Manganese Dioxide (Zn/MnO ₂) No added mercury or cadmium
Designation:	ANSI-25A, IEC-LR8D425
Nominal Voltage:	1.5 volts
Nominal IR:	200 to 350 milliohms (fresh)
Operating Temp:	-18°C to 55°C (0°F to 130°F)
Typical Weight:	6.5 grams (0.2 oz.)
Typical Volume:	2.2 cubic centimeters (0.1 cubic inch)
Jacket:	Plastic Label
Shelf Life:	5 years at 21°C
Terminal:	Flat Contact

Industry Standard Dimensions

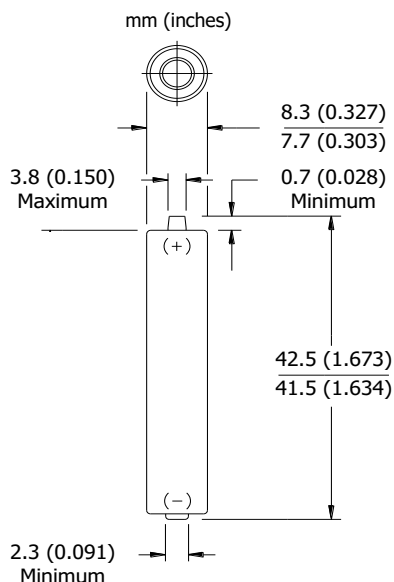


Milliamp-Hours Capacity

Continuous discharge to 0.8 volts at 21°C

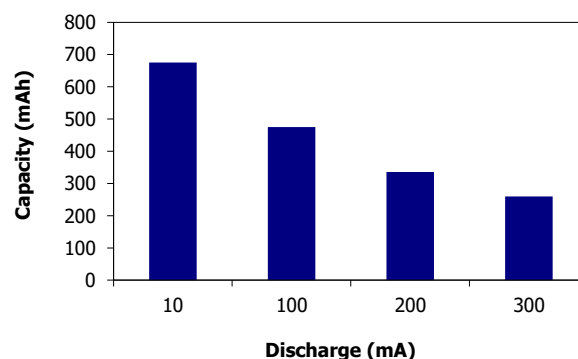


Industry Standard Tests (21°C)

LIGHTING
5.1 ohm LIF

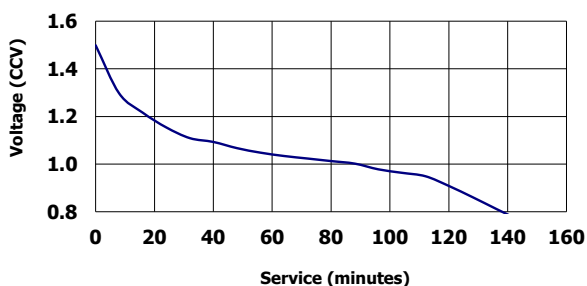

LASER POINTER
75 ohm 1 hr/day

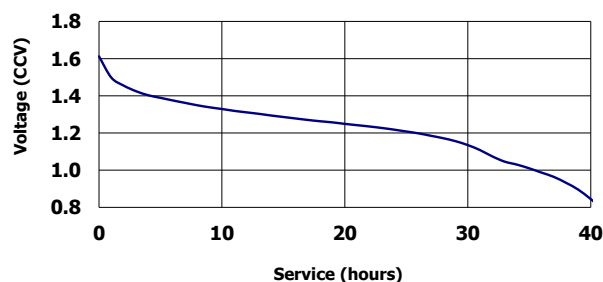

Important Notice

This datasheet contains typical information specific to products manufactured at the time of its publication.
Contents herein do not constitute a warranty and are for reference only.