


UV Reactive Spiral Wrapping Band

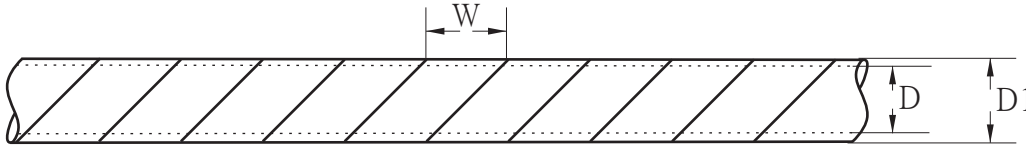

File no.	Code	ϕD	$\phi D1$	W	Wrapping Range
		mm	mm	mm	mm
	UVWB-0203	2	3	5	2-25
	UVWB-0304	3	4	6	3-30
	UVWB-0406	4	6	8	4-50
	UVWB-0608	6	8	10	6-60
93025c135a	UVWB-0810	8	10	12	7.5-60
	UVWB-1012	10	12	14	9-65
93025c136a	UVWB-1214	12	14	16	10-75
	UVWB-1416	14	16	18	12-80
	UVWB-1618	16	18	20	14-90
	UVWB-1720	17	20	22	15-100
93025c137a	UVWB-1922	19	22	24	20-130
	UVWB-2225	22	25	27	22-135

Material : PE

*Roll-pack standard
100ft (305mm)

