

Datasheet

Item no. 1229315/ 1229322

V1_0617_01_en


USB 2.0 Panel Jack, Ø22mm

Front: 2 x Female Type A

Back: 2 x 60 cm cable with Male Type A

Item no.: 1229315- Silver

1229322- Black

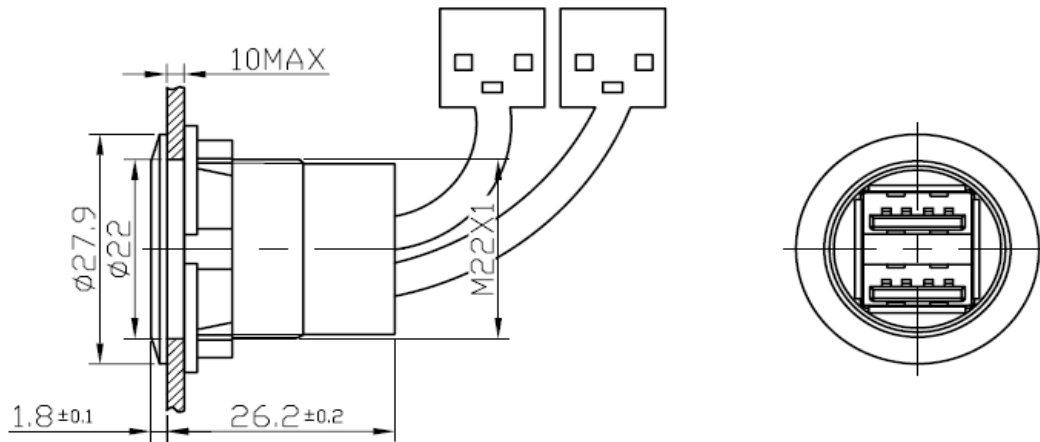

Specification	Front: 2 x Female Type A Back: 2 x 60 cm cable with Male Type A
Operating Temperature.....	-25°C ~ +55°C (NO-Freezing)
Operating Humidity.....	45~85%RH(NO Condensation)
Panel Thickness.....	1 ~8 mm
Body Material.....	Aluminium anodized (Silver color)
Transmission Rate	≥30MB/s

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.