


DATASHEET

USB 2.0 Panel Jack, Ø22mm
 Front: 2 x Female Type A
 Back: 2 x 60 cm cable with Male Type A

Version 11/15

Item no.: 1229315- Silver
 1229322- Black

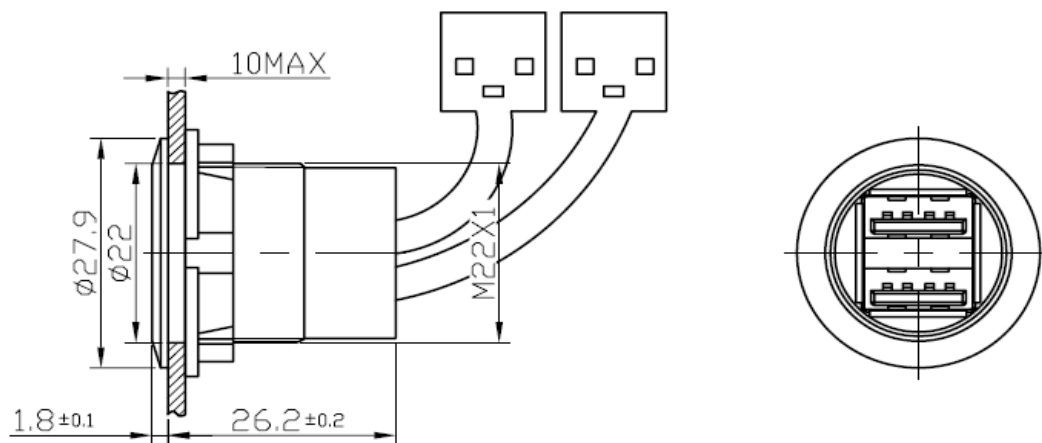

Specification	Front: 2 x Female Type A Back: 2 x 60 cm cable with Male Type A
Operating Temperature.....	-25°C ~ +55°C (NO-Freezing)
Operating Humidity.....	45~85%RH(NO Condensation)
Panel Thickness.....	1 ~8 mm
Body Material.....	Aluminium anodized (Silver color)
Transmission Rate	≥30MB/s