



► (PTC) Bayonet Bore Type
PTC-M6L40-K1.5

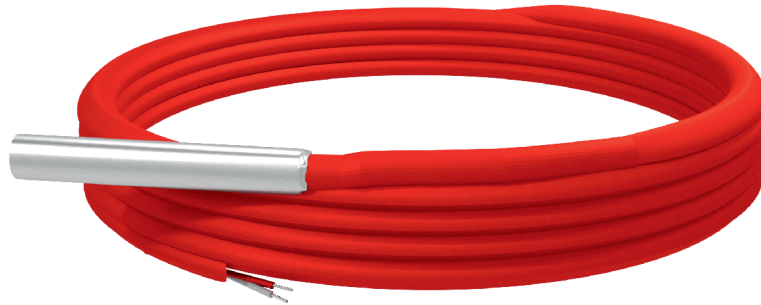


Max. operating temperature : -50 °C / +130 °C
Standard cable types : Silicone + Silicone
Sensor type : PTC-1K
Protection tube material : AISI304 (DIN1.4301) Stainless Steel

► Technical drawing

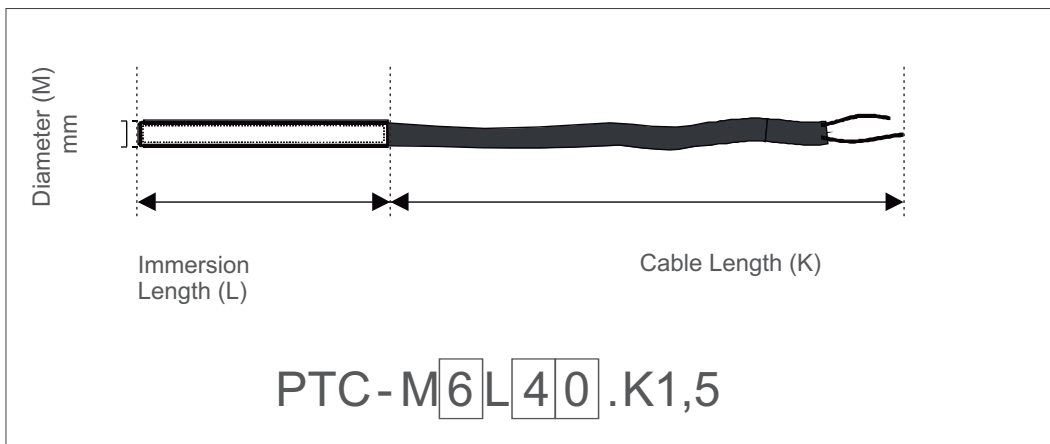

PTC Connections

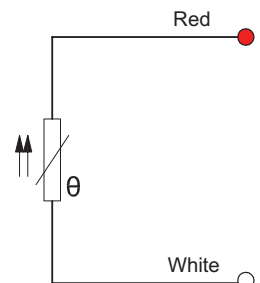

Diameter (M) : 6 mm
Immersion Length (L) : 40 mm
Cable length (K) : 1,5 meter