

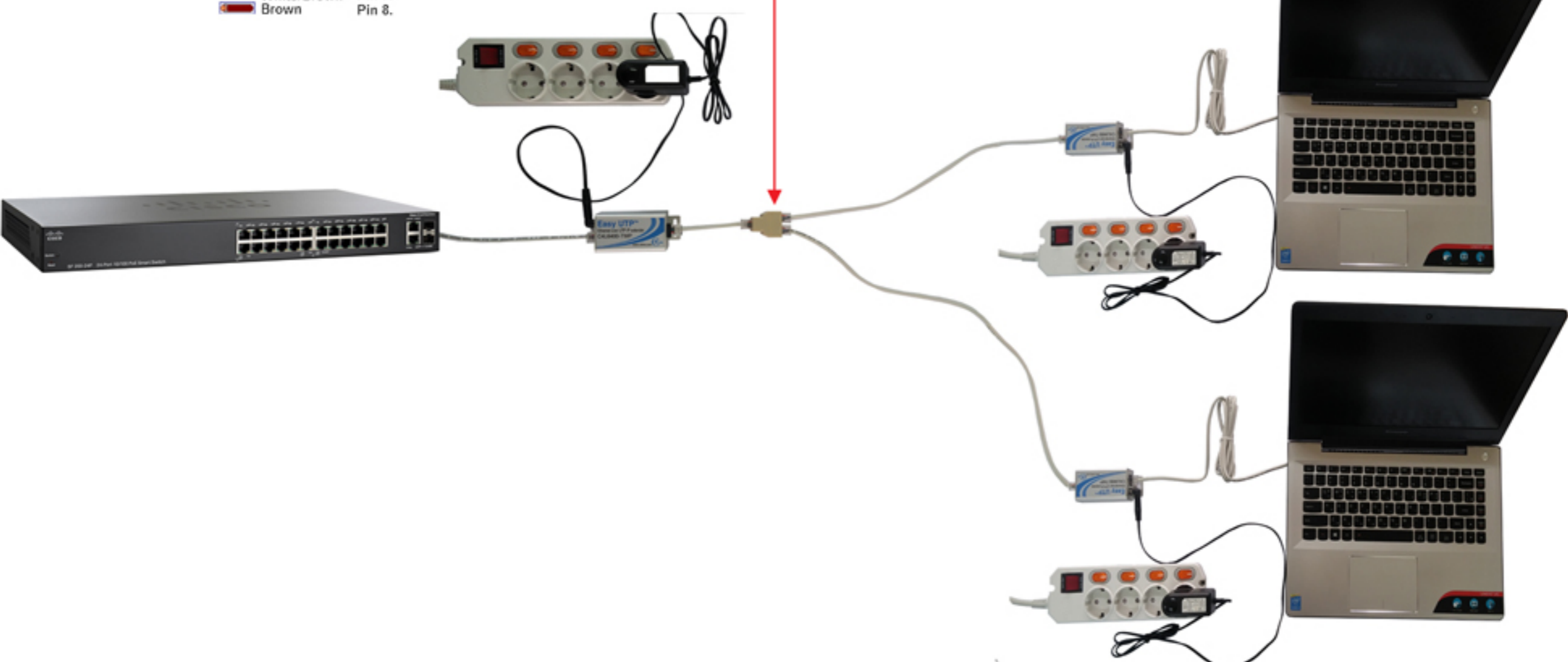
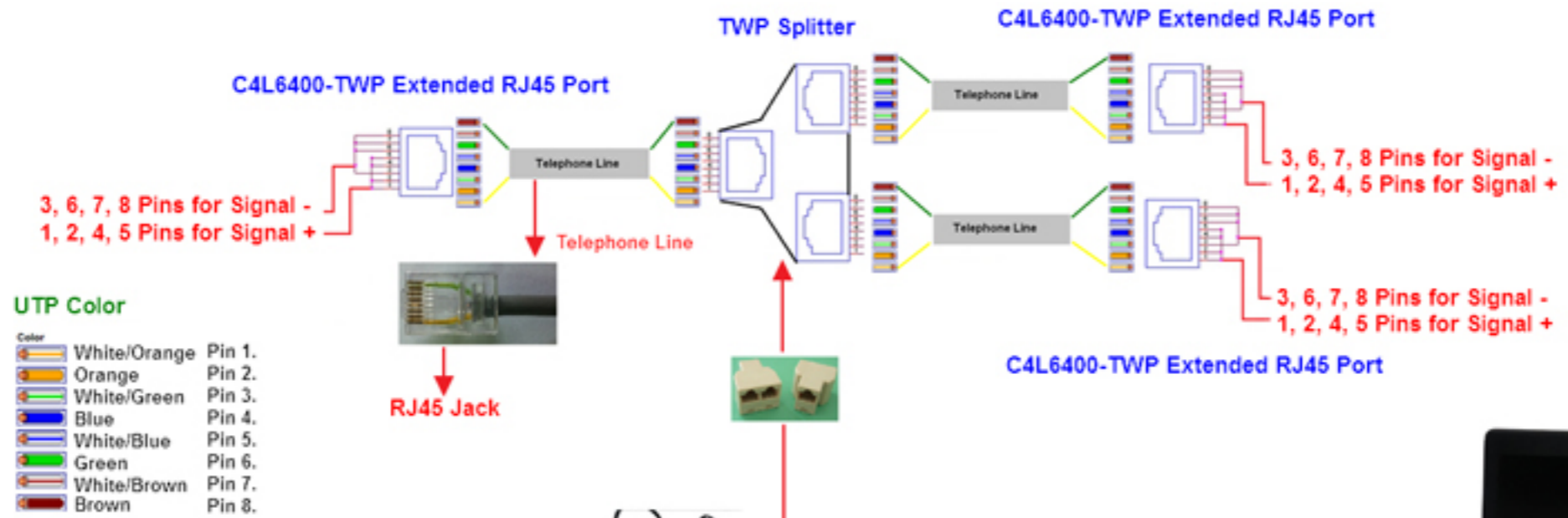



## 2Wire Telephone line connection for C4L6400-TWP extended port

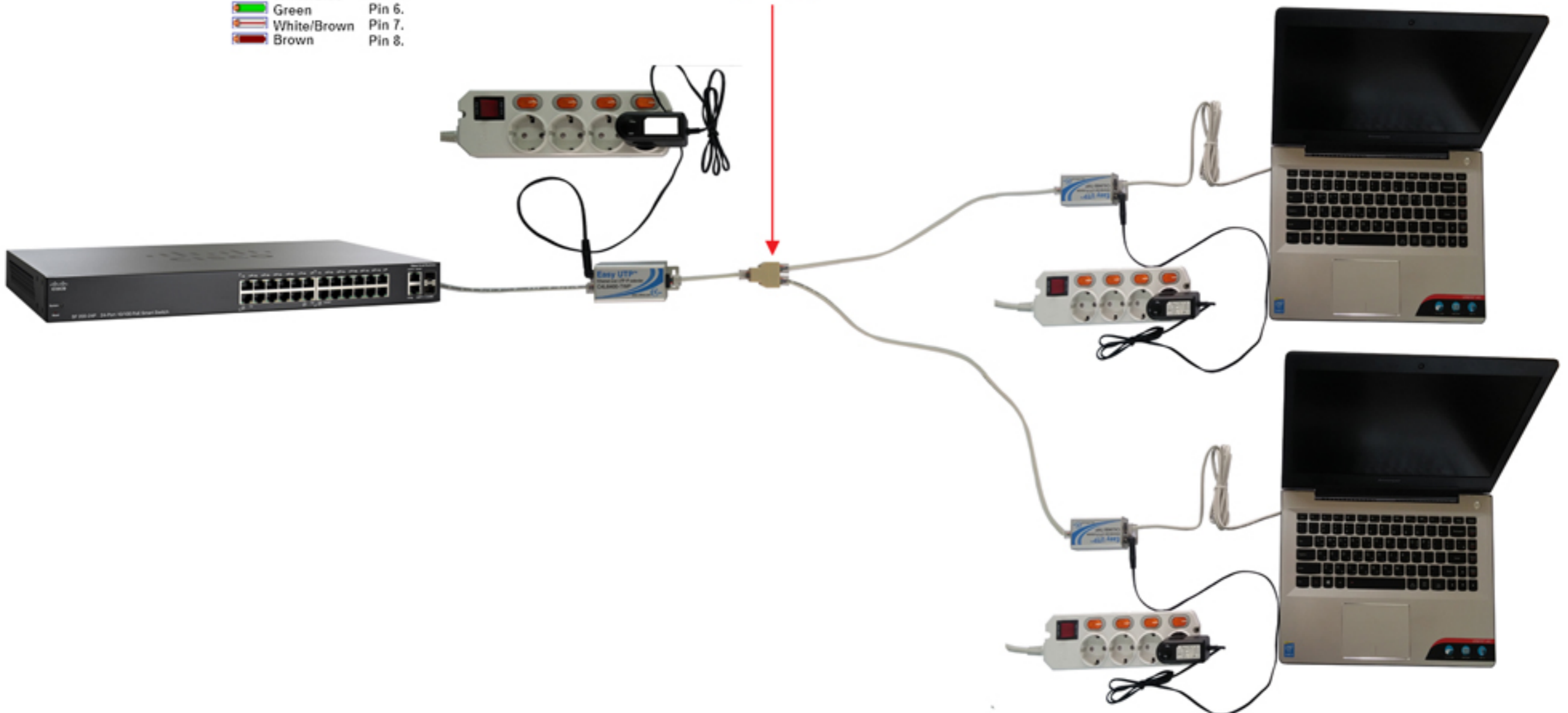

### 4Wire Telephone line connection for C4L6400-TWP extended port

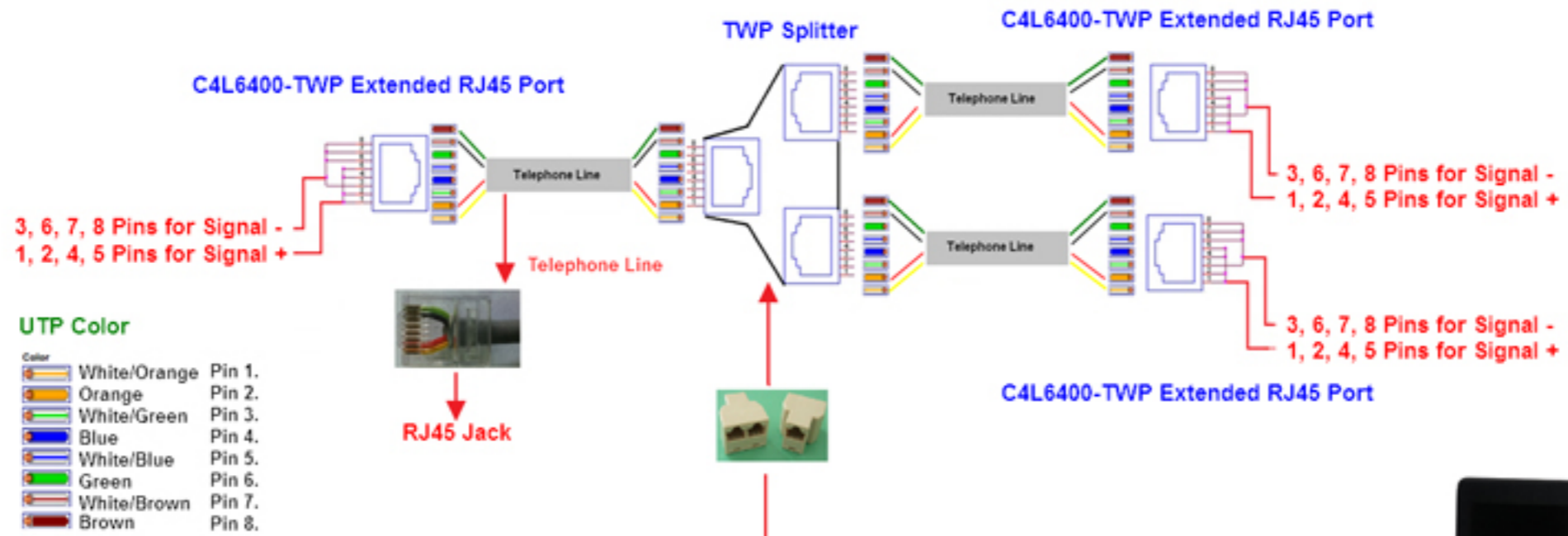

# C4L6400-TWP Ethernet Structure

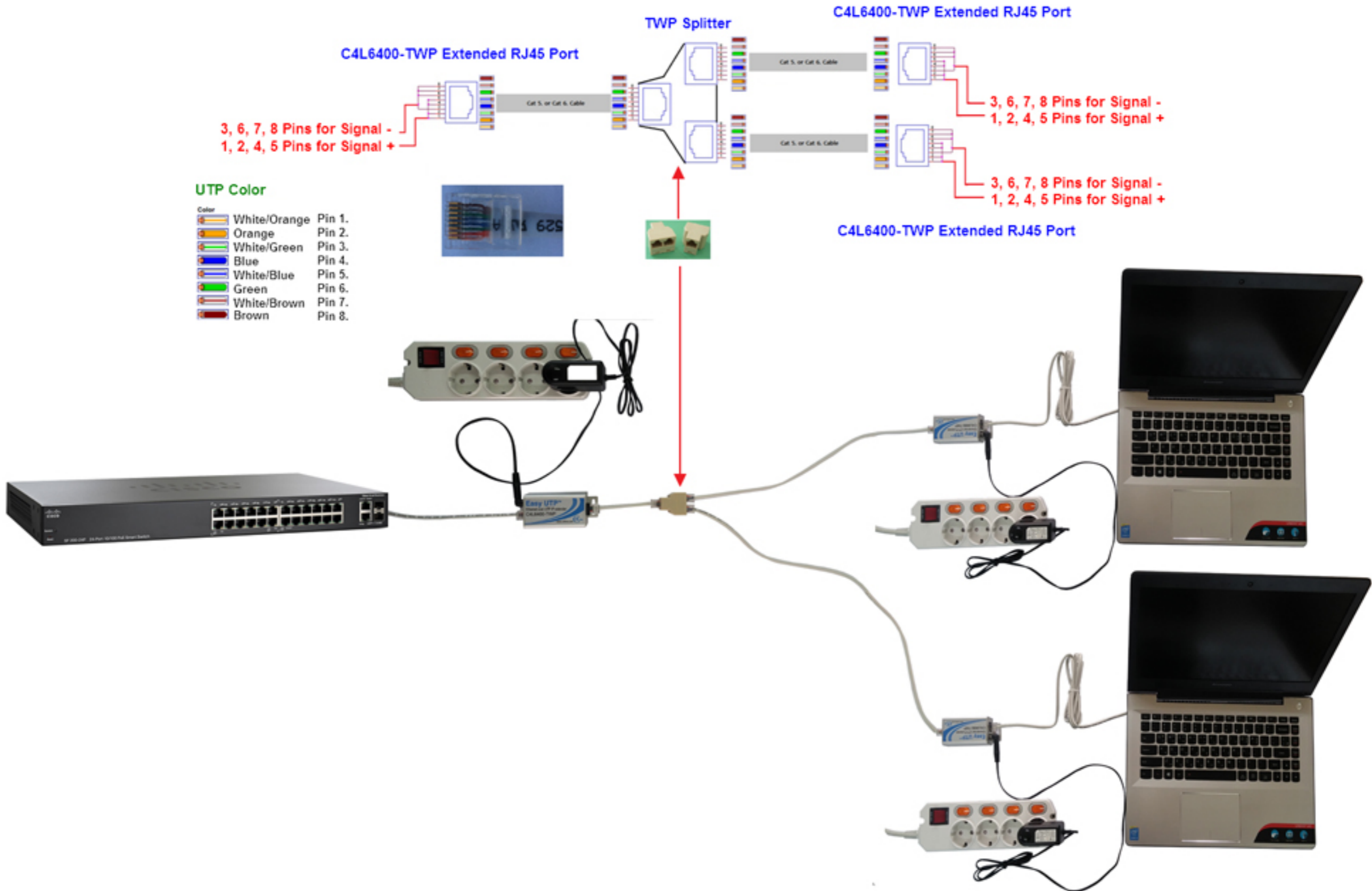

Wire Type / Bandwidth (Mbps)	10	20	30	40	50	60	70	80	93	94	94	94	94	94
4Pairs - CAT 5	671	650	620	590	560	535	503	475	419	200	100	50	20	10
4Pairs - CAT 6	738	710	682	649	616	583	553	524	461	200	100	50	20	10
Single Pair - CAT 5	640	620	592	563	535	510	480	450	400	200	100	50	20	10
Single Pair - CAT 6	704	680	651	620	588	560	528	500	440	200	100	50	20	10
Sheilded 18 AWG 2Wire	396	383	366	349	331	315	297	280	247	200	100	50	20	10
Unsheilded 18 AWG 2Wire	610	590	564	536	509	485	457	430	381	200	100	50	20	10

