



BELGIQUE/LUXEMBOURG

FACOM Belgique S.A./NV
 Weihoek 4 1930 Zaventem
 BELGIQUE
 ☎ : (02) 714 09 00
 Fax : (02) 721 24 11

DANMARK/FINLAND ISLAND/NORGE**SVERIGE**

FACOM NORDEN A/S
 Navervej 16B
 7451 Sunds
 DANMARK
 ☎ : (45) 971 444 55
 Fax : (45) 971 444 66

DEUTSCHLAND

FACOM GmbH
 Postfach 13 22 06 
 42049 Wuppertal
 Otto-Wels-Straße 9 
 42111 Wuppertal
 DEUTSCHLAND
 ☎ : (0202) 270 63 0
 Fax : (0202) 270 63 50

ESPAÑA/PORTUGAL

FACOM Herramientas SRL
 Polig. industrial de Vallecas
 C.Luis 1º, s/n-Nave 95 - 2ºPl.
 28031 Madrid
 ESPAÑA
 ☎ : (91) 778 21 13
 Fax : (91) 778 27 53

ITALIA

USAG Gruppo FACOM
 Via Volta 3,
 21020
 Monvalle (VA)
 ITALIA
 ☎ : (0332) 790 111
 Fax : (0331) 790 602

POLSKA

FACOM Oddział w Warszawie
 ul. Marconich 9 m.3
 02-954 Warszawa
 POLSKA
 ☎ : (0048 22) 642 71 14
 Fax : (0048 22) 651 74 69

NEDERLAND

FACOM Gereedschappen BV
 Kamerlingh Onnesweg 2
 Postbus 134
 4130 EC Vianen
 NEDERLAND
 ☎ : (0347) 362362
 Fax : (0347) 376020

SINGAPORE/FAR EAST

FACOM Tools FAR EAST Pte.Ltd
 15 Scotts Road
 Thong Teck Building # 08.01.02
 Singapore 228218
 SINGAPORE
 ☎ : (65) 732 0552
 Fax : (65) 732 5609

**SUISSE/ÖSTERREICH
MAGYARORSZAG
CESKA REP.**

FACOM S.A./AG
 12 route Henri-Stéphan
 1762 Givisiez/Fribourg
 SUISSE
 ☎ : (4126) 466 42 42
 Fax : (4126) 466 38 54

UNITED KINGDOM/EIRE

FACOM -UK
 Churchbridge Works-Walsall Road
 CANNOCK STAFFORDSHIRE WS11 3JR
 UNITED KINGDOM
 ☎ : (01922) 702 150
 Fax : (01922) 702 152


UNITED STATES

FACOM TOOLS Inc.
 3535 West 47th Street
 Chicago Illinois 60632
 U.S.A.
 ☎ : (773) 523 1307
 Fax : (773) 523 2103

**FRANCE ET
INTERNATIONAL**

Société FACOM
 6-8, rue Gustave Eiffel B.P.99
 91423 Morangis cedex
 FRANCE
 ☎ : 01 64 54 45 45
 Fax : 01 69 09 60 93
<http://www.facom.fr>

U.306A140 - U.306-180
U.306-260 - U.306A130N
U.306-170N - U.310-170
U.310-250 - U.310-250VH
U.310-230N
















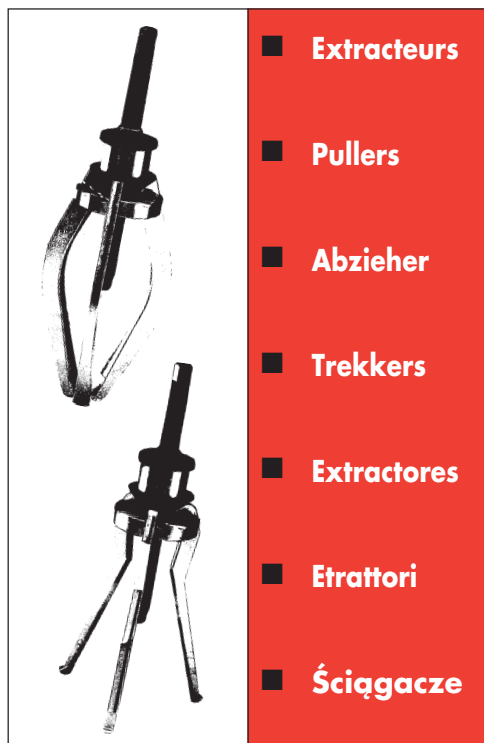


- **Extracteurs**
- **Pullers**
- **Abzieher**
- **Trekkers**
- **Extractores**
- **Etrattori**
- **Ściągacze**


Notice d'instructions
 Instruction manual
 Bedienungsanleitung
 Gebruiksaanwijzing
 Guia de instrucciones
 Istruzioni per l'utilizzo
 Instrukcja obsługi
NU-U.306A/0901



Utilisation - Use - Gebrauch - Gebruik - Utilizacion - Uso - Użytkowanie

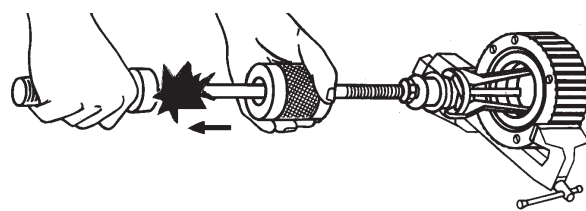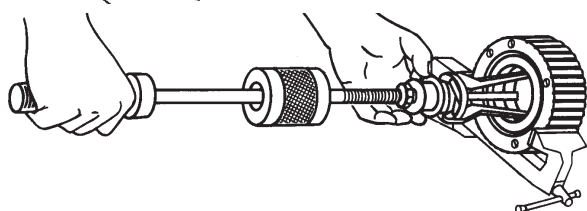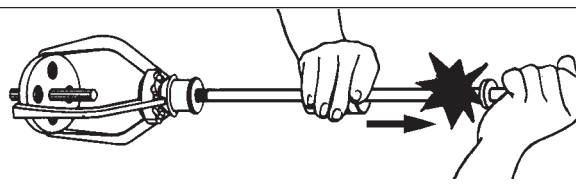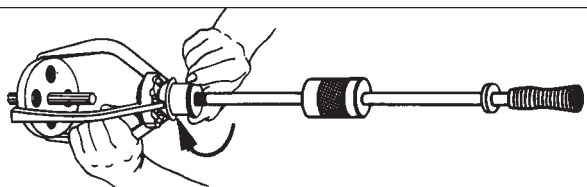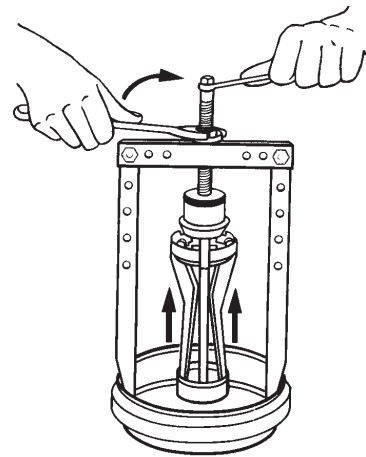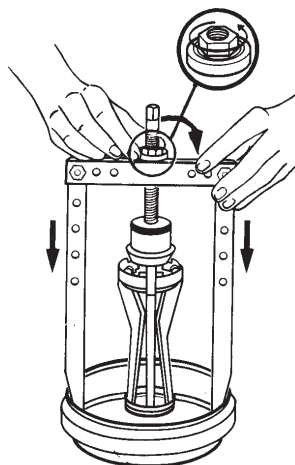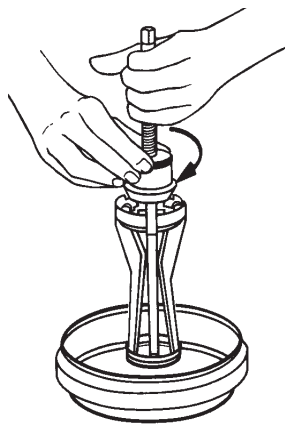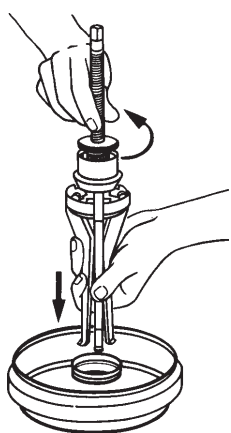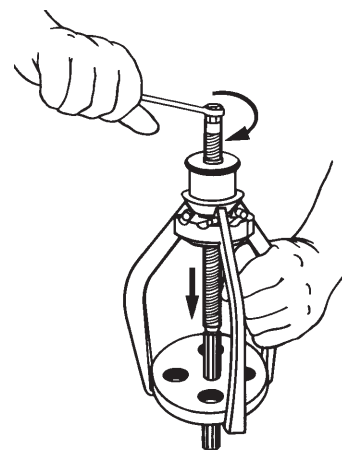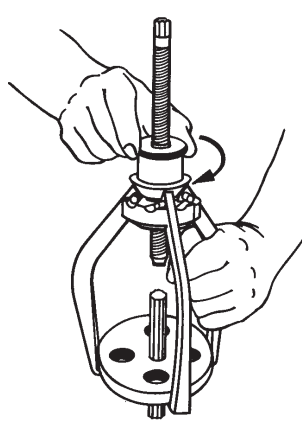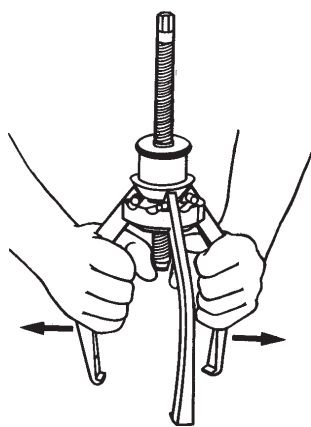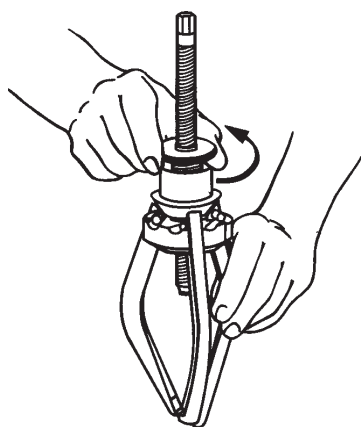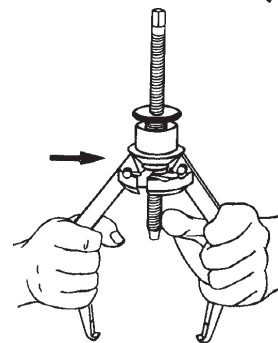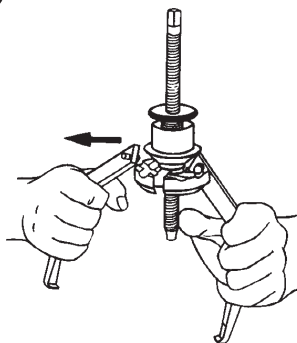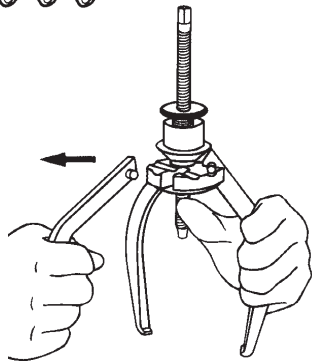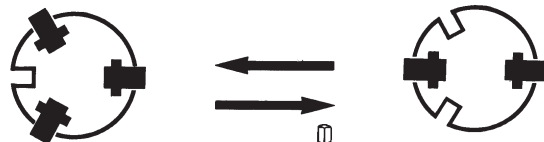


U.306-2 - U.306-4

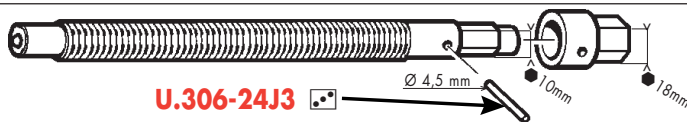
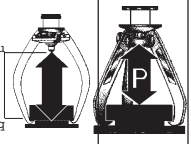





U.306-24J3



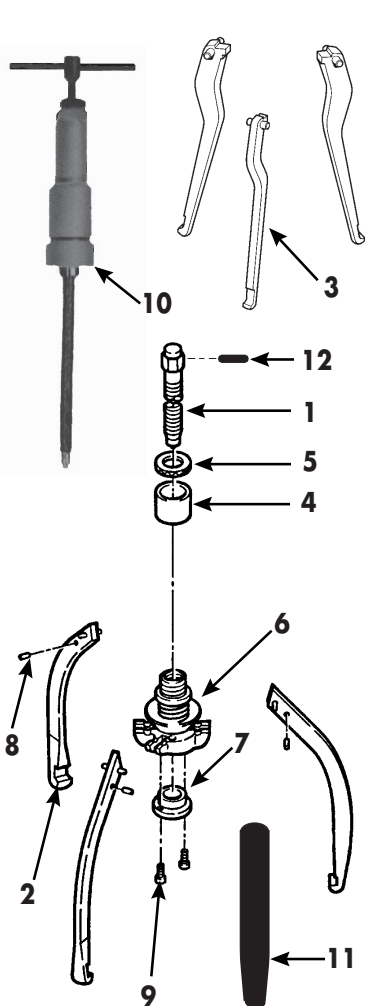


130 Nm maxi

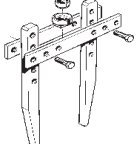Caractéristiques - Specifications - Kenndaten - Specificaties - Caracteristicas - Caratteristiche - Dane techniczne



|  | Ø mini | Ø maxi | Ø mini | Ø maxi |  |  |  |  |
|---|--------|--------|--------|--------|---|---|---|---|
| | mm | mm | mm | mm | | | | |
| U.306A140 | 7 | 140 | | | 147 | 3 | U.306M | U.40+U.306A1 |
| U.306-180 | 10 | 180 | | | 200 | 4 | U.306M | U.40+U.306A1 |
| U.306-260 | 20 | 260 | | | 250 | 4 | U.306M | U.40+U.306A1 |
| U.306A130N | | | 23 | 130 | 140 | 3 | U.306M | U.40+U.306A1 |
| U.306-170N | | | 50 | 170 | 190 | 3 | U.306M | U.40+U.306A1 |
| U.310-170 | 15 | 170 | | | 170 | 10 | U.2 | |
| U.310-250 | 15 | 250 | | | 250 | 10 | U.2 | |
| U.310-250VH | 15 | 250 | | | 250 | 10 | U.2 | |
| U.310-230N | | | 50 | 230 | 200 | 10 | U.2 | |

Pièces détachées - Spare parts - Ersatzteile - Onderdelen-lijst Piezas de recambios - Pezzi di ricambio - Części zamienne

| N° | U.306A140 | U.306-180 | U.306-260 | U.306A130N | U.306-170N | U.310-170 | U.306-250 | U.306-250VH | U.310-230N |
|----|--|--|--|--|--|------------------|------------------|--------------------|-------------------|
| 1 | U.306-4 | U.306-2 | U.306-2 | U.306-4 | U.306-2 | U.20B1 | U.310-250-10 | | U.20B1 |
| 2 | U.306G1 (3) | U.306G10 (3) | U.306G15 (3) | | | U.310G1 (3) | U.310G2 (3) | U.310G2 (3) | |
| 3 | | | | U.306G2 (3) | U.306G20 (3) | | | | U.310G3 (3) |
| 4 | U.306-06 | U.306-06 | U.306-06 | U.306-06 | U.306-06 | U.310-250-06 | U.310-250-06 | U.310-250-06 | U.310-250-06 |
| 5 | U.306-140-07 | U.306-140-07 | U.306-140-07 | U.306-140-07 | U.306-140-07 | U.310-170-07 | U.310-170-07 | U.310-170-07 | U.310-170-07 |
| 6 | U.306-19 | U.306-19 | U.306-19 | U.306-19 | U.306-19 | U.310-19 | U.310-19 | U.310-19 | U.310-19 |
| 7 | | | | | | U.310-170-08 | U.310-170-08 | U.310-170-08 | U.310-170-08 |
| 8 | | | | | | U.310GP1 (3) | U.310GP1 (3) | U.310GP1 (3) | U.310GP1 (3) |
| 9 | | | | | | VIS.CHC,M6-16(2) | VIS.CHC,M6-16(2) | VIS.CHC,M6-16(2) | VIS.CHC,M6-16(2) |
| 10 | | | | | | | | U.3 | |
| 11 | | | U.306-3-03 | | | | | | |
| 12 | U.306-24J3  | U.306-24J3  | U.306-24J3  | U.306-24J3  | U.306-24J3  | | | | |