


DATASHEET

Version 7/15

BN: 1302101

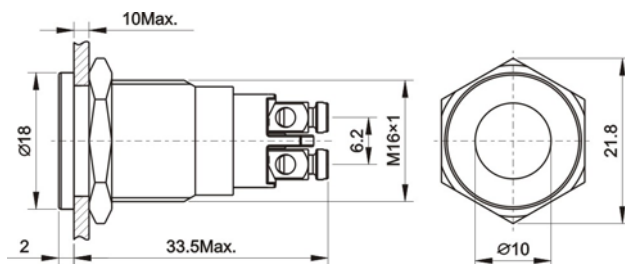

Specification	GQ16F-D/R/12V/S
The Front Shape	Flat Round
Terminal Type	Screw Terminal
Dielectric Intensity	2000VAC
Operating Temp	-20°C ~ +55°C
Humidity	45 ~ 85% RH
Panel Thickness	1~10mm
Rated Voltage	12V
Rated Current	15mA
LED Color	Red
LED Life	40000 hours
Torque	5~14Nm
Lampshade Material.....	PC
Body Material	Stainless Steel
Base Material	PBT

Product Description: Signal lamp, Φ 16mm, 12V.