


DATASHEET

Product Description: Signal lamp, Φ 19mm, 12V.

Version 7/15

BN: 1302119

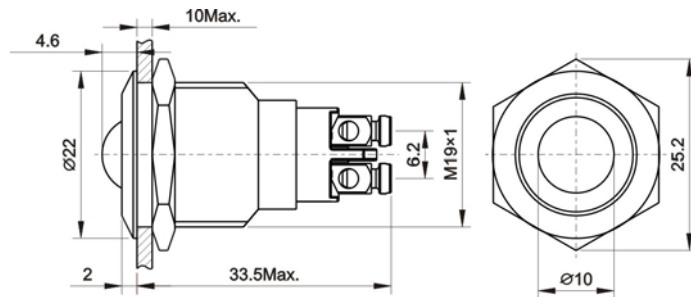

Specification	GQ19B-D/W/12V/S
The Front Shape	Domed
Terminal Type	Screw Terminal
Dielectric Intensity	2000VAC
Operating Temp	-20°C ~ +55°C
Humidity	45 ~ 85% RH
Panel Thickness	1~10mm
Rated Voltage	12V
Rated Current	15mA
LED Color	White
LED Life	40000 hours
Torque	5~14Nm
Lampshade Material.....	PC
Body Material	Stainless Steel
Base Material	PBT