


DATASHEET

Product Description: Signal lamp, $\Phi 16\text{mm}$, 12V.

Version 7/15

BN: 1302130

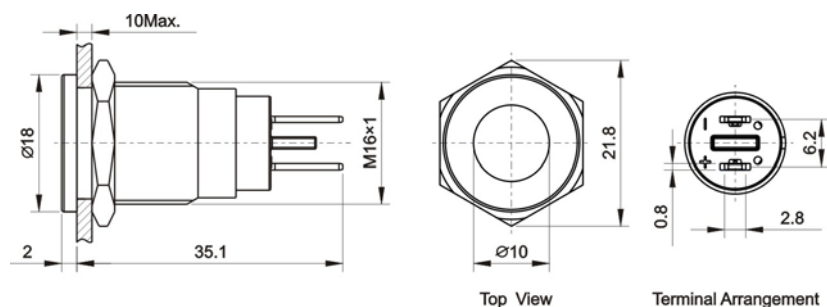

Specification	GQ16F-D/J/B/12V/N
The Front Shape	Flat Round
Terminal Type	Pin Terminal(2.8x0.8mm)
Dielectric Intensity	2000VAC
Operating Temp	-20°C ~ +55°C
Humidity	45 ~ 85% RH
Panel Thickness	1~10mm
Rated Voltage	12V
Rated Current	15mA
LED Color	Blue
LED Life	40000 hours
Torque	5~14Nm
Lampshade Material.....	PC
Body Material	Nickel Plated Brass
Base Material	PBT