


# Datasheet

Item no. 1302136

V1\_0717\_01\_en

Product Description: Signal lamp,  $\Phi$  16mm, 12V.

BN: 1302136

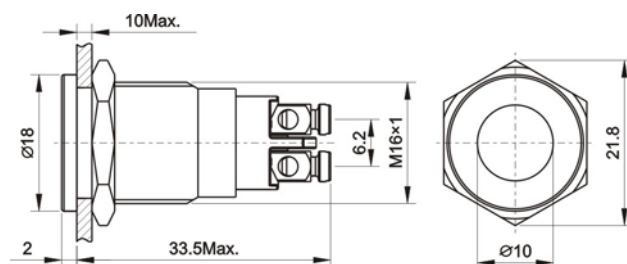

|                            |                     |
|----------------------------|---------------------|
| The Front Shape .....      | Flat Round          |
| Terminal Type .....        | Screw Terminal      |
| Dielectric Intensity ..... | 2000VAC             |
| Operating Temp .....       | -20°C ~ +55°C       |
| Humidity .....             | 45 ~ 85% RH         |
| Panel Thickness .....      | 1~10mm              |
| Rated Voltage .....        | 12V AC/ DC          |
| Rated Current .....        | 15mA                |
| LED Color .....            | Red                 |
| LED Life .....             | 40000 hours         |
| Torque .....               | 5~14Nm              |
| Lampshade Material .....   | PC                  |
| Body Material .....        | Nickel Plated Brass |
| Base Material .....        | PBT                 |

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.