


DATASHEET

Product Description: Signal lamp, $\Phi 16\text{mm}$, 12V.

Version 7/15

BN: 1302137

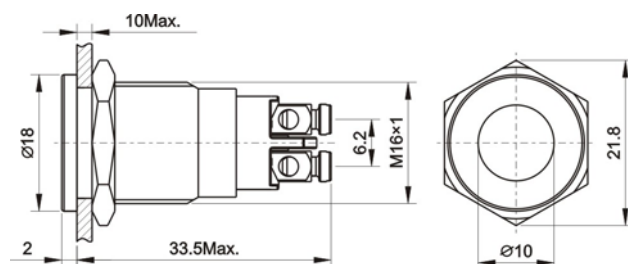

Specification	GQ16F-D/G/12V/N
The Front Shape	Flat Round
Terminal Type	Screw Terminal
Dielectric Intensity	2000VAC
Operating Temp	-20°C ~ +55°C
Humidity	45 ~ 85% RH
Panel Thickness	1~10mm
Rated Voltage	12V
Rated Current	15mA
LED Color	Green
LED Life	40000 hours
Torque	5~14Nm
Lampshade Material.....	PC
Body Material	Nickel Plated Brass
Base Material	PBT