


# DATASHEET

Φ 16mm, Push Button Switch ,Illuminated power symbol, Momentary,  
 1NO1NC, IP65, Green 12V for LED, IP65  
 Item no. 98008c37

Version 06/14

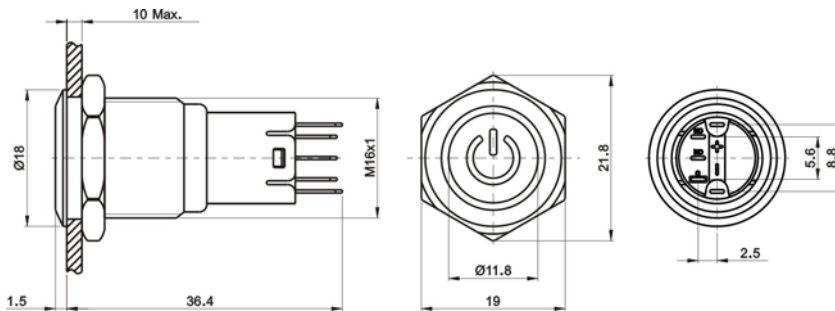

Specification .....	LAS2GQF-11DT/G/12V/S/P
The Front Shape .....	Flat Round
Terminal Type .....	Pin Terminal(1.8×0.4mm)
Switching .....	C(single-break fast-motion changeover contact)
Switch Rating .....	2A/48VDC
Contact Resistance .....	≤50m Ω
Insulation Resistance .....	≥1000M Ω
Dielectric Intensity .....	2000VAC
Operating and storage temperature.....	-20°C ~ +55°C
Operating and storage humidity.....	45 ~ 85% RH
Mechanical Life .....	200,000 cycles
Electrical Life .....	50,000 cycles
Panel Thickness .....	1~10mm
Operation Pressure .....	About 2.5~4N
Operation Travel .....	About 2.8mm
Contact Material .....	Silver Alloy
Button Material .....	Stainless Steel
Crust Material .....	Stainless Steel