
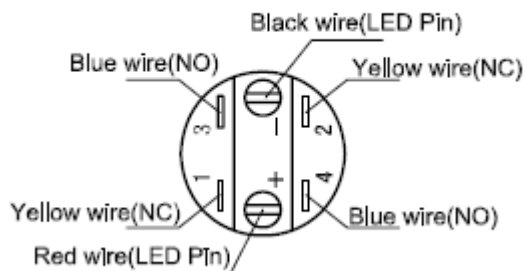


Datasheet

Item no. 1303047

V1_0717_01_en

Φ19 mm, push button switch, circle illuminated, blue led 230V, IP67, momentary type, Stainless steel crust, 1NO1NC, BN no. 1303047

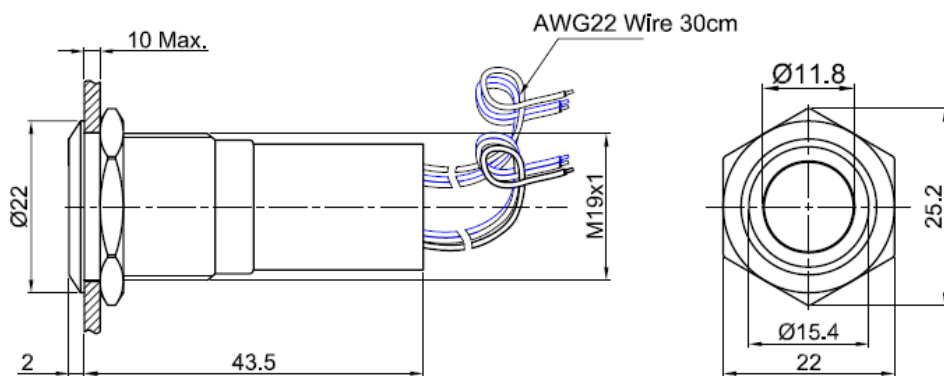

Specification	LAS1-GQ-11E/B/230V/IP67 sealed terminal With 6*30cm wire
Mounting diameter	19 mm
Switching voltage	250 V/AC
Switching current	3 A
Led colour	blue
Led voltage	230V AC
Connection	soldering
Terminal type	pin terminal(2.8×0.5mm)
Contact resistance	≤ 50 mΩ
Insulation resistance	≥ 1000 MΩ
Dielectric intensity	2000 V/AC

Datasheet

Item no. 1303047

V1_0717_01_en

Operating and storage temperature	-20 to +70 °C
Operating and storage humidity	45 to 85 % RH
Panel thickness	1 ~ 10 mm
Operation pressure	about 5 N
Operation travel	about 2.5 mm
Electrical lifespan	50000 cycles
Durability	1,000,000 cycles
Crust material	stainless steel

This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com).

All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

© Copyright 2017 by Conrad Electronic SE.