
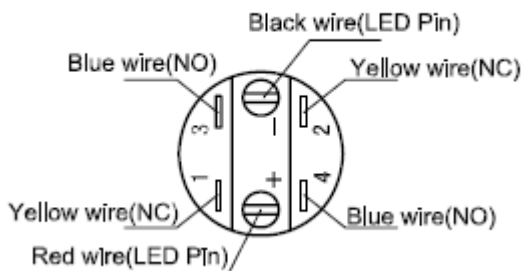


**Φ19 mm, push button switch, circle illuminated, blue led  
230V, IP67, momentary type, Stainless steel crust, 1NO1NC,  
BN no. 1303047**

**Version 08/15**

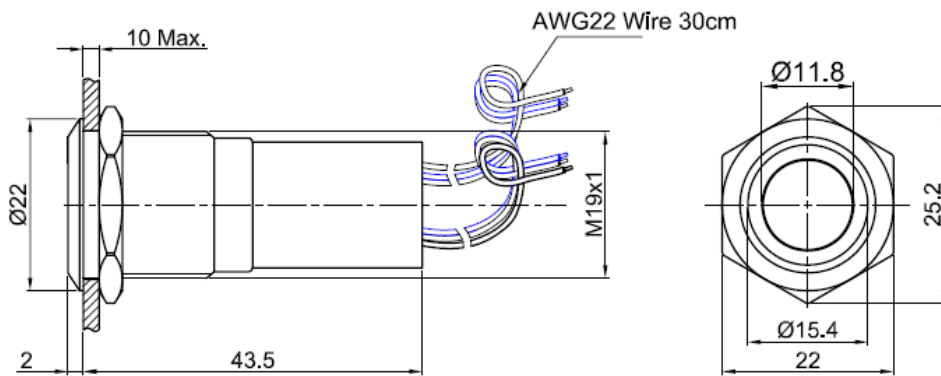

Specification .....	LAS1-GQ-11E/B/230V/IP67 sealed terminal With 6*30cm wire
Mounting diameter .....	19 mm
Switching voltage .....	250 V/AC
Switching current .....	3 A
Led colour .....	blue
Led voltage .....	230V AC
Connection .....	soldering
Terminal type .....	pin terminal(2.8×0.5mm)
Contact resistance .....	≤ 50 mΩ
Insulation resistance .....	≥ 1000 MΩ
Dielectric intensity .....	2000 V/AC

Operating and storage temperature .....	-20 to +70 °C
Operating and storage humidity .....	45 to 85 % RH
Panel thickness .....	1 ~ 10 mm
Operation pressure .....	about 5 N
Operation travel .....	about 2.5 mm
Electrical lifespan .....	50000 cycles
Durability .....	1,000,000 cycles
Crust material .....	stainless steel



This data sheet is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau ([www.conrad.com](http://www.conrad.com)). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This data represent the technical status at the time of printing. Changes in technology and equipment reserved.

© Copyright 2015 by Conrad Electronic SE.