

**Female Header
Pitch 2.54 mm angled**

Single row, height 8.5 mm



SPECIFICATION:

Current rating: 1 A
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 30 mΩ max.
 Dielectric voltage: 500 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:

Housing: PBT UL94V-0
 Contacts: Copper alloy

FINISH:





Contacts: Gold Flash

HANDLING:

Processing: Wave soldering
 Packing: Tube

TOLERANCE:

.X ± 0.38
 .XX ± 0.25

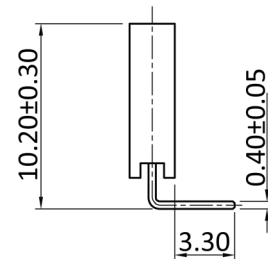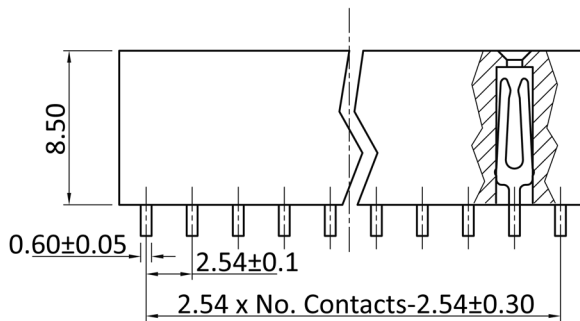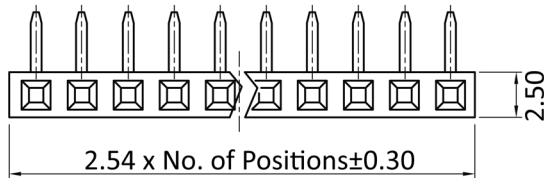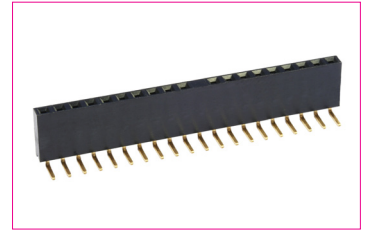

Order-Information

Identifier:	No. of contacts:	Version:	Plastic Height:
BL	#	W	8
Female Header Pitch 2.54 mm single row straight	2/1: 1 x 2 3/1: 1 x 3 4/1: 1 x 4 : 40/1: 1 x 40	W: Angled	8: 8.5 mm