

**Female Header  
Pitch 2.54 mm straight**

Single row, height 8.5 mm



**SPECIFICATION:**

Current rating: 1 A  
 Insulation resistance: 1000 MΩ min.  
 Contact resistance: 20 mΩ max.  
 Dielectric voltage: 500 V AC  
 Operation temperature: -40 °C to +105 °C

**MATERIAL:**

Housing: PBT UL94V-0  
 Contacts: Copper alloy

**FINISH:**



 

Contacts: Gold Flash

**HANDLING:**

Processing: Wave soldering  
 Packing: Tube

**TOLERANCE:**

.X ± 0.38  
 .XX ± 0.25

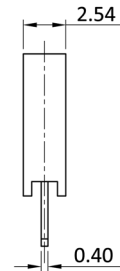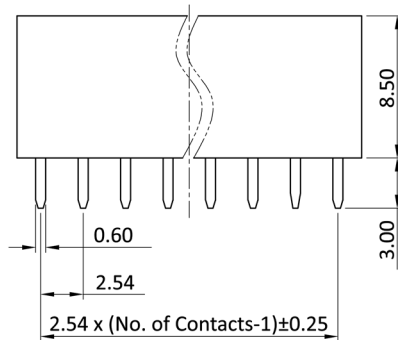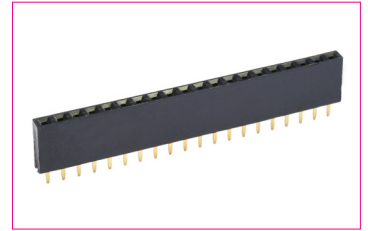

**Order-Information**

Identifier:	No. of contacts:	Version:	Plastic Height:
BL	#	G	8
Female Header Pitch 2.54 mm single row straight	2/1: 1 x 2 3/1: 1 x 3 4/1: 1 x 4 : 40/1: 1 x 40	G: Straight	8: 8.5 mm