

# Modular Plugs, unshielded

6P4C / 6P6C



**SPECIFICATION:**

Current rating: 1.5 A  
 Insulation resistance: 1000 MΩ min.  
 Contact resistance: 20 mΩ max.  
 Dielectric voltage: 1000 V AC  
 Operation temperature: -40 °C to +70 °C



**MATERIAL:**



Housing: Polycarbonate UL94V-2  
 Contacts: Phosphorbronze

**FINISH:**

Contacts: Gold Flash

**HANDLING:**

Packing: Bulk

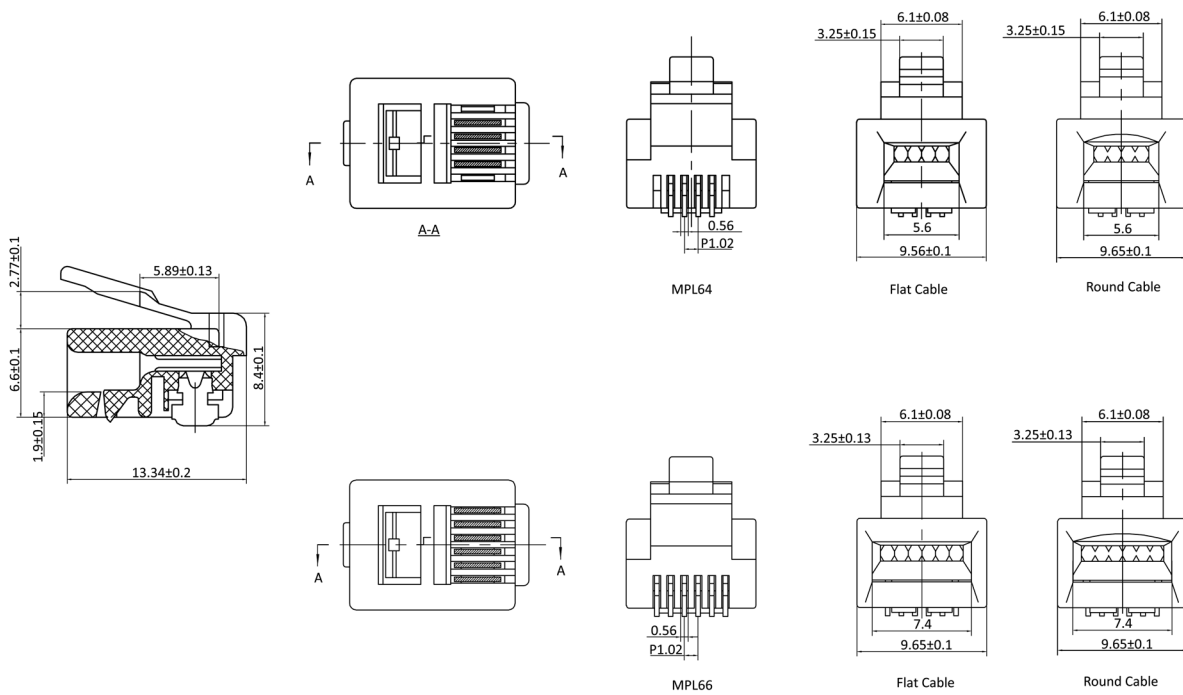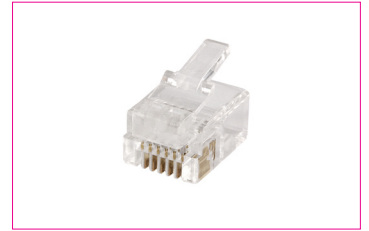

**Order-Information**

Identifier:	Conductors:	Version:
MPL6	#	#
Modular Plug 6P unshielded	4: 4C 6: 6C	empty: for flat oval cable R: for round cable