

Flat Cable Connector System DIN 41651 Box Header without Locking

Pitch 2.54 mm, angled



RoHS
COMPLIANT

SPECIFICATION:

Current rating: 1 A
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 500 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:

Housing: PA-46 UL94V-0
 Pins: Copper alloy

FINISH:






Contacts: Gold Flash

HANDLING:

Processing: Wave soldering
 Packing: Tray

TOLERANCE:

.X ± 0.38
 .XX ± 0.25

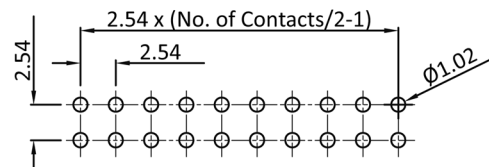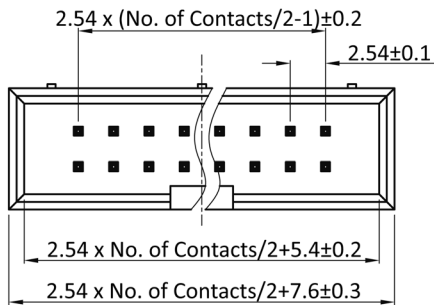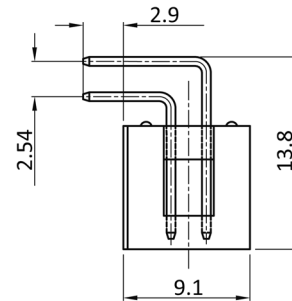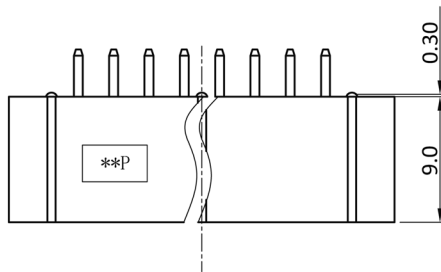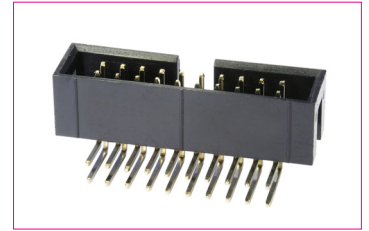

Order-Information

Identifier:	No. of contacts:	Version:	Contact Plating:
WS	#	W	#
Box header pitch 2.54 mm angled	10: 2 x 5 12: 2 x 6 14: 2 x 7 16: 2 x 8 20: 2 x 10 26: 2 x 13 30: 2 x 15 34: 2 x 17 40: 2 x 20 50: 2 x 25 60: 2 x 30 64: 2 x 32	W: angled	empty: Gold Flash * S: Selective T: Tin plated

* = standard