

DVI Female Connectors

Panel mount, analogue/digital, angled



RoHS
COMPLIANT

SPECIFICATION:

Current rating: 1 A
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 30 mΩ max.
 Dielectric voltage: 500 V AC
 Operation temperature: -20 °C to +85 °C

MATERIAL:

Insulator: Thermoplastic UL94V-0
 Shell: Steel
 Contacts: Copper alloy

FINISH:



Contacts: Gold Flash
 Shell: Nickel plated

HANDLING:

Processing: Wave soldering
 Packing: Tray

TOLERANCE:

.X ± 0.38
 .XX ± 0.25

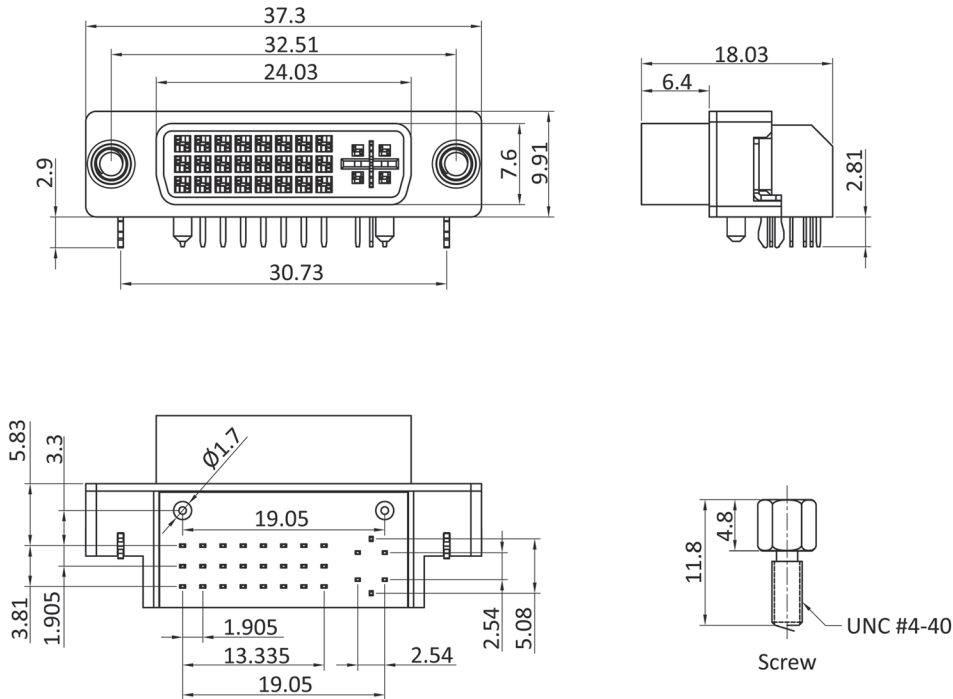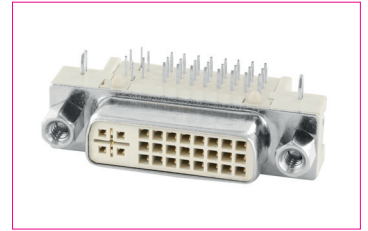

Order-Information

Identifier:

DVIAD1

Panel jack angled, analogue/digital, PCB mount