

Modular Jacks, shielded

Multiport 2, tap up



SPECIFICATION:

Current rating: 1.5 A
 Insulation resistance: 500 MΩ min.
 Contact resistance: 40 mΩ max.
 Dielectric voltage: 1000 V AC
 Operation Temperature: 0 °C to +70 °C

MATERIAL:

Housing: Thermoplastic
 Contacts: Phosphorbronze
 Shield: Brass

FINISH:



Contacts: Gold over nickel
 Terminal: Tin over nickel
 Shield: Nickel plated

HANDLING:

Processing: Wave soldering
 Packing: Tray

TOLERANCE:

.X ±0.38
 .XX ±0.25

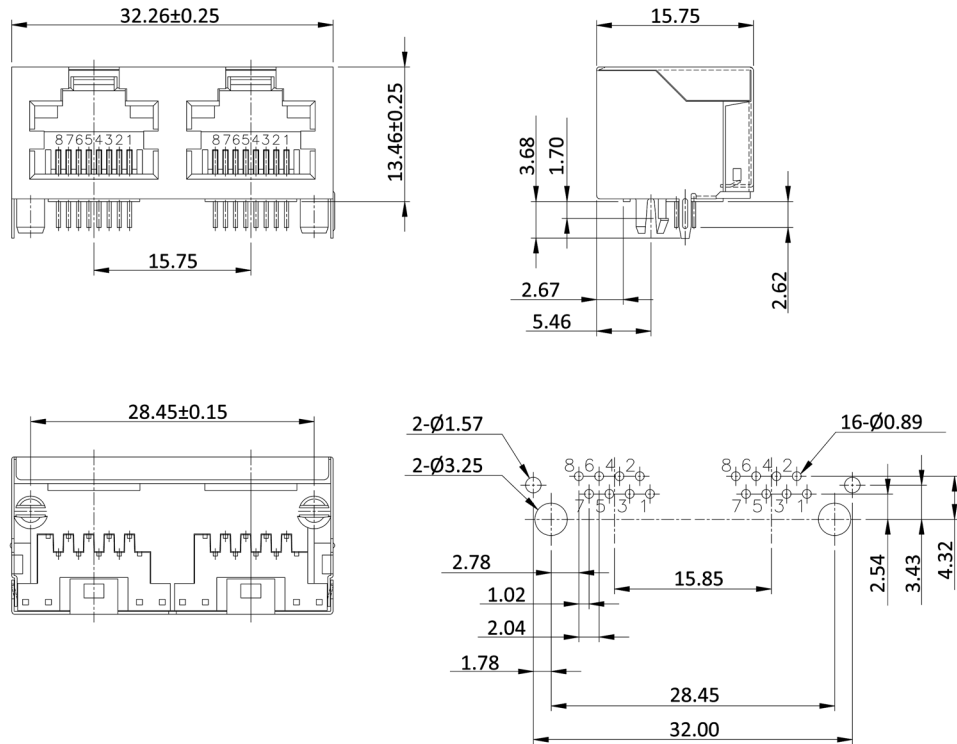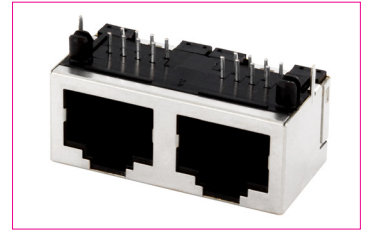

PCB Layout (Top View)

Order-Information

Identifier:

MPU288

Modular Jack 2xRJ45 shielded, PCB mount

Contact plating:

#

- A: 6 μ" Gold *
- B: 15 μ" Gold
- C: 30 μ" Gold
- D: 50 μ" Gold

* = standard