

**Mini Jumper
Pitch 2.54 mm**

Jumper open version



SPECIFICATION:

Current rating: 3 A
Insulation resistance: 5000 MΩ min.
Contact resistance: 20 mΩ max.
Dielectric voltage: 500 V AC
Operation temperature: -55 °C to +105 °C

**RoHS
COMPLIANT**

MATERIAL:

Housing: PBT UL94V-0
Contact: Brass

FINISH:



Contact: Gold over nickel

Packing:

Bulk

TOLERANCE:

.X ± 0.30
.XX ± 0.20

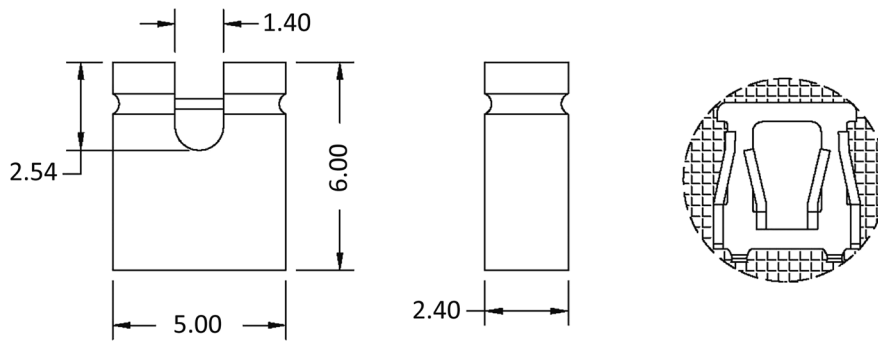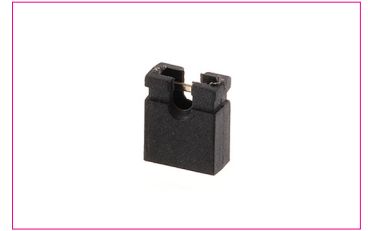

Order-Information

Identifier:

SH

Jumper open Pitch 2.54 mm

Colour:

#

SW: black

RT: red

BL: blue