

# USB 2.0 Sockets Type A

PCB, angled, Multiport 3



RoHS  
COMPLIANT

**SPECIFICATION:**

Current rating: 1.5 A  
 Voltage rating: 30 V  
 Insulation resistance: 1000 MΩ min.  
 Contact resistance: 30 mΩ max.  
 Dielectric voltage: 750 V AC  
 Operation temperature: -55 °C to +85 °C

**MECHANICAL:**

Mating force: ≤ 35 N  
 Unmating force: ≥ 10 N

**MATERIAL:**

Insulator: PBT black UL94V-0  
 Shell: Brass  
 Contacts: Phosphorbronze

**FINISH:**


Shell: Tin/nickel plated  
 Contacts: Gold Flash in contact area  
 Tin plated on solder tails

**HANDLING:**

Processing: Wave soldering  
 Packing: Tray

**TOLERANCE:**

.X ± 0.25  
 .XX ± 0.20

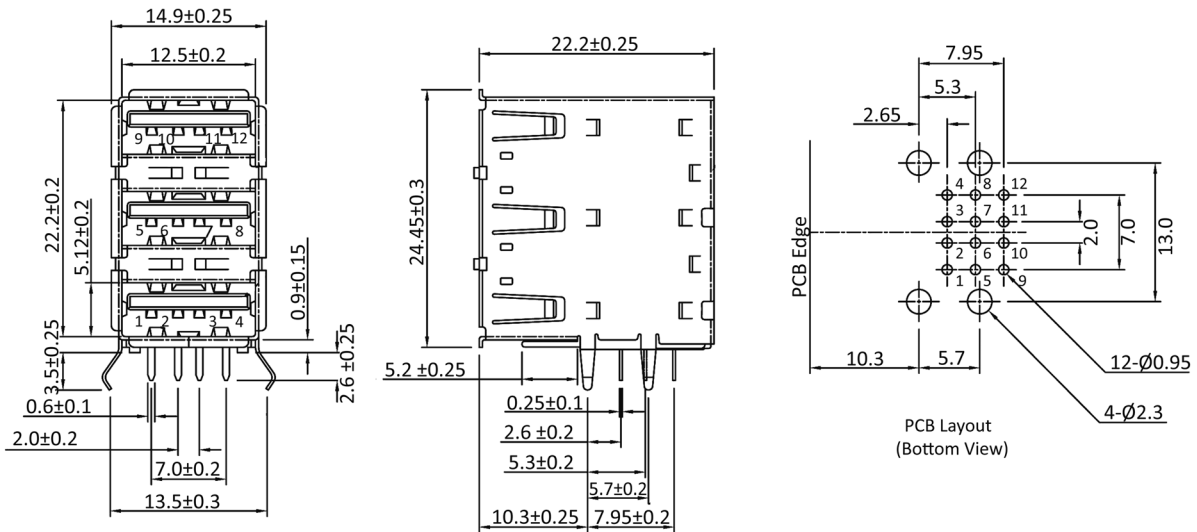

**Order-Information**

Identifier:

USBBU3A

Socket 3 x Type A angled