

Flat Cable Connector System DIN 41651 Box Header without Locking

Pitch 2.54 mm, straight



RoHS
COMPLIANT

SPECIFICATION:

Current rating: 3 A
 Insulation resistance: 5000 MΩ min.
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 500 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:

Housing: PBT UL94V-0
 Pins: Brass

FINISH:






Contacts: Gold Flash

HANDLING:

Processing: Wave soldering
 Packing: Tray

TOLERANCE:

.X ± 0.25
 .XX ± 0.20

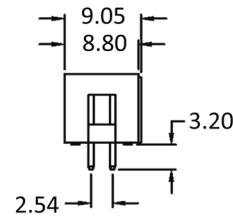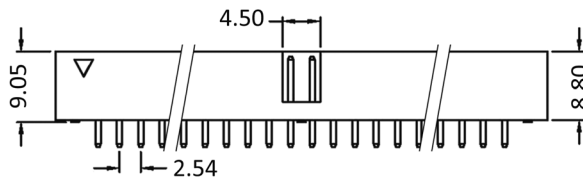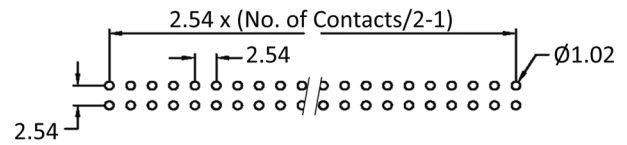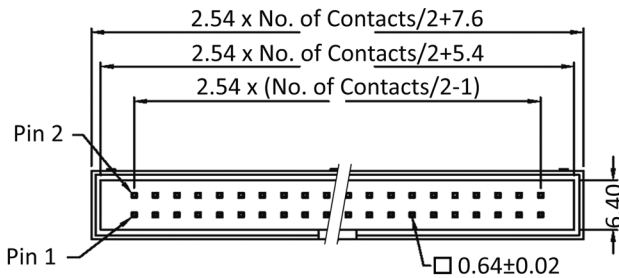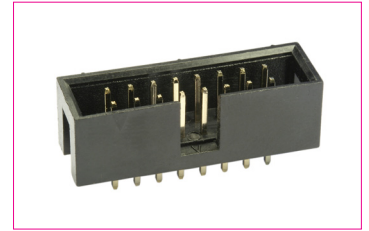

Order-Information

Identifier:	No. of contacts:	Version:	Contact Plating:
WS	#	G	#
Box Header Pitch 2.54 mm	6: 2 x 3	G: Straight	empty: Gold Flash *
	8: 2 x 4		S: Selective
	10: 2 x 5		T: Tin plated
	12: 2 x 6		
	14: 2 x 7		
	16: 2 x 8		
	20: 2 x 10		
	24: 2 x 12		
	26: 2 x 13		
	30: 2 x 15		
	34: 2 x 17		
	40: 2 x 20		
	44: 2 x 22		
	50: 2 x 25		
	56: 2 x 28		
	60: 2 x 30		
	64: 2 x 32		

* = standard