

Flat Cable Connector System DIN 41651 Box Header with Locking

Pitch 2.54 mm, IDC, long latches



SPECIFICATION:

Current rating: 3 A
 Insulation resistance: 5000 MΩ min.
 Contact resistance: 30 mΩ max.
 Dielectric voltage: 1000 V AC
 Operation temperature: -55 °C to +105 °C

MATERIAL:

Housing: PBT UL94V-0
 Pins: Copper alloy

FINISH:

Contacts: Gold Flash


 



HANDLING:

Processing: IDC
 Packing: Tray

TOLERANCE:

.X ± 0.30
 .XX ± 0.20

RoHS
COMPLIANT

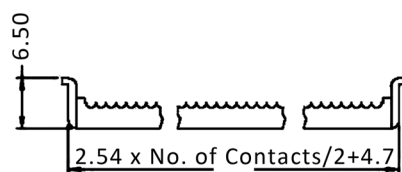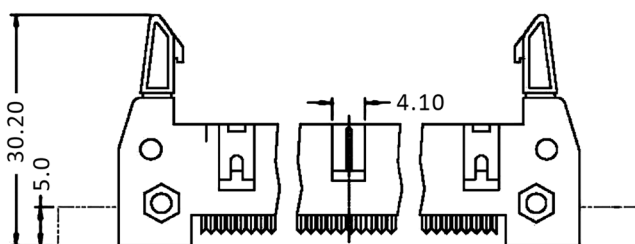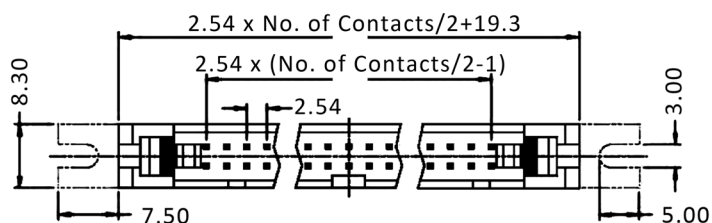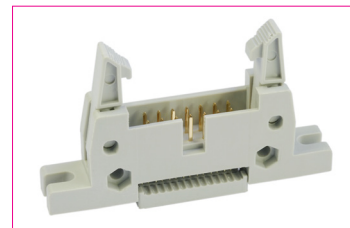

Order-Information

Identifier:	No. of contacts:	Version:	Locking:
WS	#	SK	VL
Box Header with Flange, Pitch 2.54 mm	10: 10 pin	SK: IDC	VL: long latches
	14: 14 pin		
	16: 16 pin		
	20: 20 pin		
	24: 24 pin		
	26: 26 pin		
	30: 30 pin		
	34: 34 pin		
	40: 40 pin		
	50: 50 pin		
	60: 60 pin		
	64: 64 pin		