

# Flat Cable Connector System DIN 41651 Box Header without Locking

Pitch 2,54 mm, IDC



RoHS  
COMPLIANT

### SPECIFICATION:

Current rating: 1 A  
 Insulation resistance: 1000 MΩ min.  
 Contact resistance: 30 mΩ max.  
 Dielectric voltage: 500 V AC  
 Operation temperature: -55 °C to +105 °C

### MATERIAL:



Housing: PBT UL94V-0  
 Pins: Brass

### FINISH:

Contacts: Selective gold plated

### HANDLING:

Processing: IDC  
 Packing: Tray

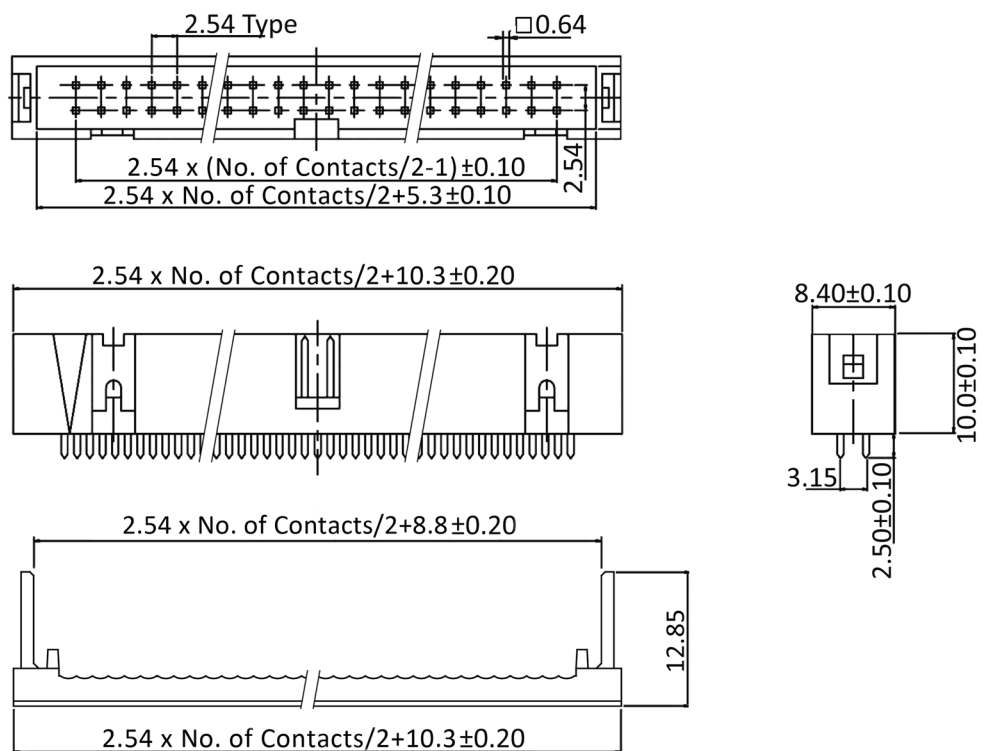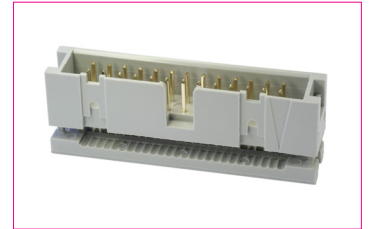

### Order-Information

Identifier:	No. of contacts:	Version:
WS	#	SK
Box Header Pitch 2.54 mm	10: 2 x 5	SK: IDC
	14: 2 x 7	
	16: 2 x 8	
	20: 2 x 10	
	24: 2 x 12	
	26: 2 x 13	
	30: 2 x 15	
	34: 2 x 17	
	40: 2 x 20	
	50: 2 x 25	
	60: 2 x 30	
	64: 2 x 32	