

**Female Header
Pitch 2.0 mm straight**

Single row, height 4.3 mm



SPECIFICATION:

Current rating: 2 A
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 500 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:



Housing: Nylon 6T UL94V-0
 Contacts: Copper alloy

HANDLING:

Processing: Wave soldering
 Packing: Tube

TOLERANCE:

.X ± 0.25
 .XX ± 0.20

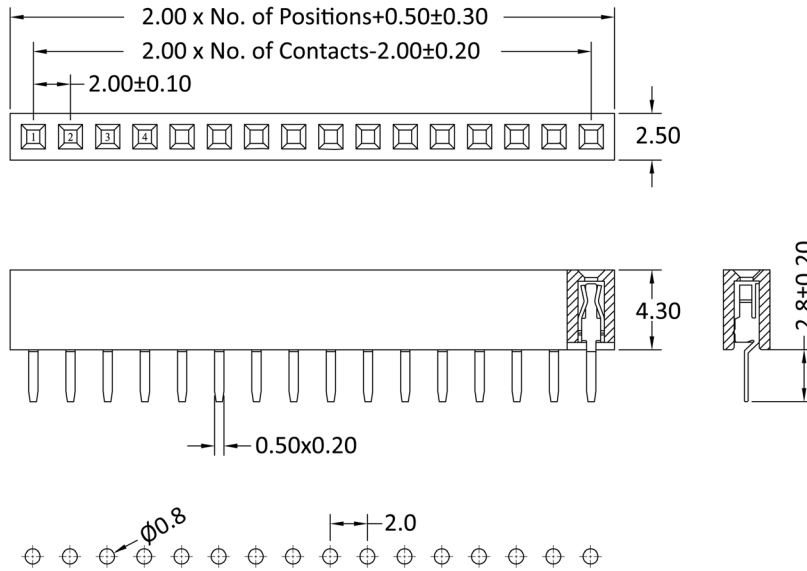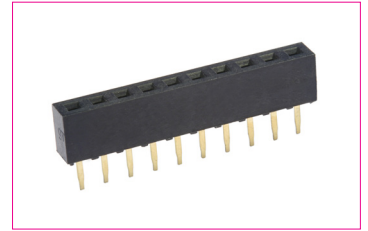

Recommended PCB Layout
(PCB Tolerance ± 0.05)

Order-Information

Identifier:	No. of contacts:	Contact Plating:
FHS43S	#	#
Female Header Pitch 2.0 mm single row straight Height 4.3 mm	3: 1 x 3 4: 1 x 4 5: 1 x 5 : 40: 1 x 40	G: Gold Flash * S: Selective

* = standard