

SPECIFICATION:

Current rating: 1 A
 Insulation resistance: 100 MΩ min.
 Contact resistance: 30 mΩ max.
 Dielectric voltage: 250 V AC
 Operation temperature: -25 °C to +85 °C

MATERIAL:

Insulator: LCP black UL94V-0
 Contacts: Copper alloy

FINISH:

Contacts: Gold Flash




HANDLING:

Processing: Reflow soldering
 Packing: Reel





TOLERANCE:

.X ± 0.30
 .XX ± 0.20

RoHS
COMPLIANT

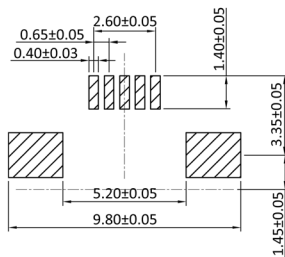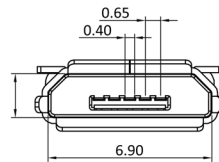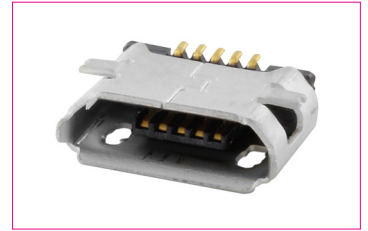

PCB Layout

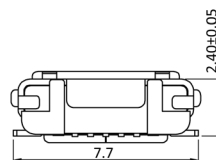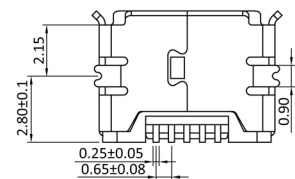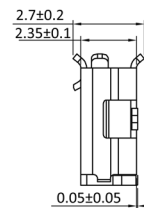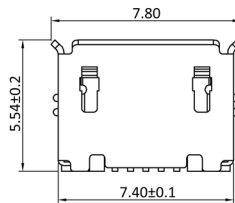

Order-Information

Identifier:

MICUB5BBS

USB 2.0 socket 5 pin B-Type SMT