

# Modular Plugs, shielded

6P6C



### SPECIFICATION:

Current rating: 1.5 A  
Insulation resistance: 500 M $\Omega$  min.  
Dielectric voltage: 1000 V AC  
Operation temperature: -20 °C to +70 °C  
Cable to tensile strength: 5.8 kg max.

### MATERIAL:

Housing: Polycarbonate UL94V-2  
Contacts: Copper alloy  
Shield: Brass







### FINISH:

Contacts: Gold plated 3  $\mu$ "  
Shield: Nickel plated

### HANDLING:

Packing: Bulk

RoHS  
COMPLIANT

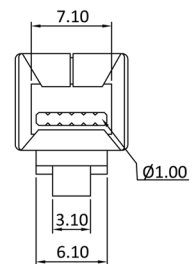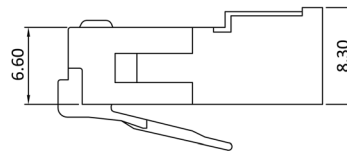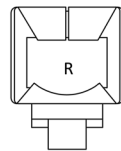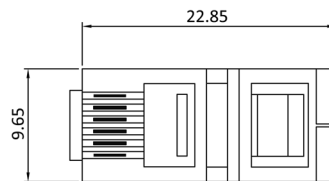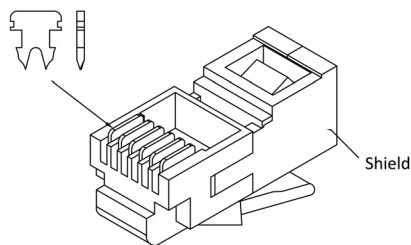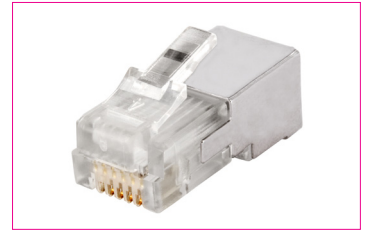

### Order-Information

Identifier:

MPL6/6

Modular Plug 6P6C

Version:

RG

RG: for round cable, shielded