

Flat Cable Connector System DIN 41651 IDC Socket Connectors

Pitch 2.0 mm



RoHS
COMPLIANT

SPECIFICATION:

Current rating: 1 A
 Insulation resistance: 1000 MΩ min.
 Contact resistance: 20 mΩ max.
 Dielectric voltage: 500 V AC
 Operation temperature: -40 °C to +105 °C

MATERIAL:

Housing: PBT UL94V-0
 Pins: Copper alloy

FINISH:



Contacts: Gold Flash

HANDLING:

Packing: Tray

TOLERANCE:

.X ± 0.25
 .XX ± 0.20

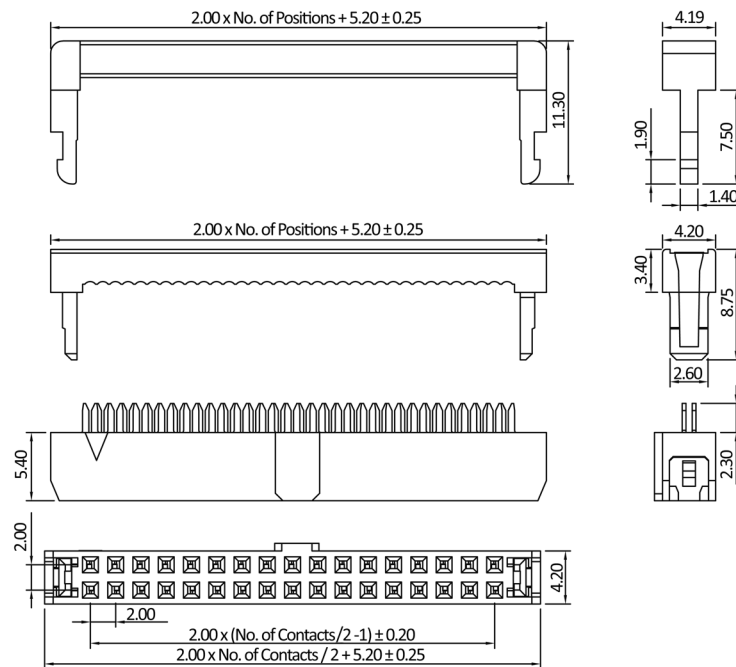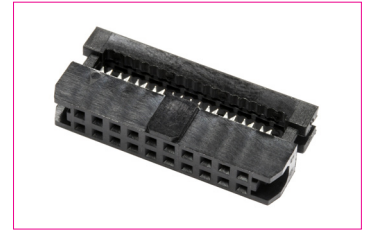

Order-Information

Identifier:	No. of contacts:	Pitch:	Version:
PV	#	RM2	#
IDC Socket	6: 2 x 3	RM2: Pitch 2.0 mm	empty: w/o Strain Relief *
	8: 2 x 4		S: with Strain Relief
	10: 2 x 5		
	12: 2 x 6		
	14: 2 x 7		
	16: 2 x 8		
	18: 2 x 9		
	20: 2 x 10		
	24: 2 x 12		
	26: 2 x 13		
	30: 2 x 15		
	34: 2 x 17		
	40: 2 x 20		
	44: 2 x 22		
	50: 2 x 25		
	60: 2 x 30		

* = standard