

**Mini Jumper
Pitch 2.54 mm**

Jumper closed version



SPECIFICATION:

Current rating: 3 A
Insulation resistance: 5000 MΩ min.
Contact resistance: 20 mΩ max.
Dielectric voltage: 1000 V AC
Operation temperature: -40 °C to +105 °C

**RoHS
COMPLIANT**

MATERIAL:

Housing: PBT UL94V-0
Contact: Brass


FINISH:

Contact: Gold over nickel

Packing: Bulk

TOLERANCE:

.X ± 0.35
.XX ± 0.25

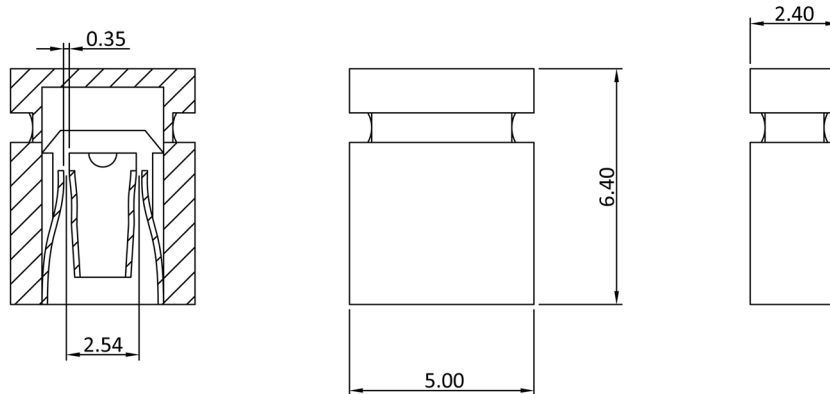

Order-Information

Identifier:	Colour:	Version:
SH	#	G
Jumper Pitch 2.54 mm	SW: black RT: red BL: blue	G: closed Type