

**SPECIFICATION:**

Voltage rating: 335 V RMS max.  
 Insulation resistance: 1000 MΩ min.  
 Contact resistance: Inner conductor 6 mΩ max.  
 Outer conductor 1 mΩ max.  
 Dielectric voltage: 1000 V RMS max.

**MATERIAL:**

Insulator: Teflon  
 Inner conductor: Brass  
 Shell: Brass

**FINISH:**

Inner conductor: Gold plated 2 μ"  
 Outer conductor: Gold plated 2 μ"



**HANDLING:**

Packing: Bag

**TOLERANCE:**

.X ± 0.40  
 .XX ± 0.20

**RoHS  
COMPLIANT**

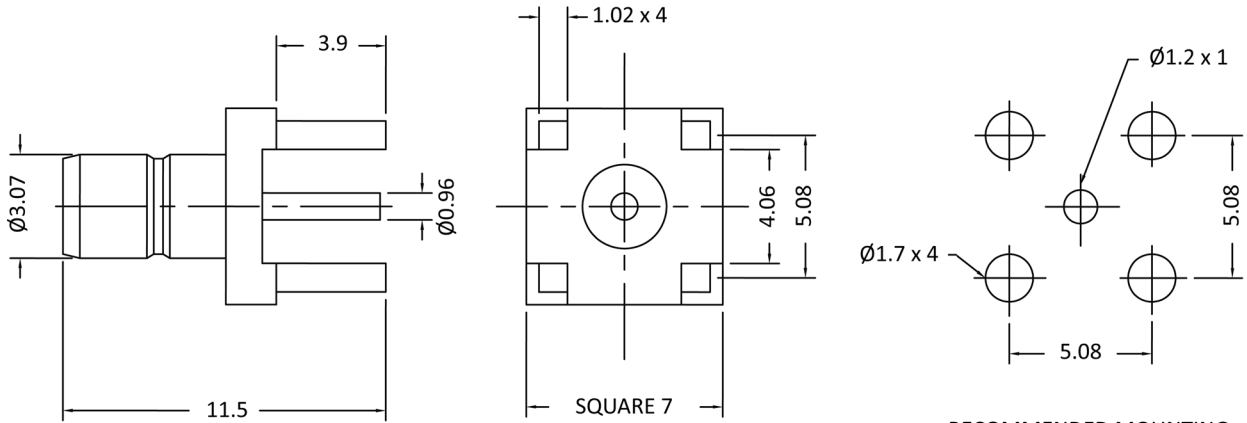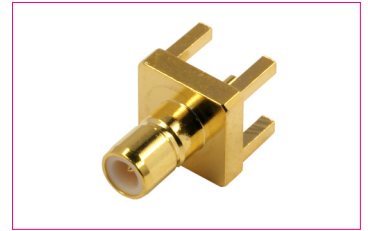

RECOMMENDED MOUNTING HOLE LAYOUT

**Order-Information**

Identifier:

SMB4MG

SMB Male receptacle gold plated 50 Ohms, PCB mount